

Tongue steel, with stop

Item description/product images



Description

Material:

Steel.

Version:

Electro zinc-plated.

Note:


*A in mm by housing length H=18 mm, H=30 mm and H=50 mm.

Accessory:

Quarter-turn lock zinc, lockable K2216.

quarter-turn lock zinc, lockable, long version K2217.

Drawings

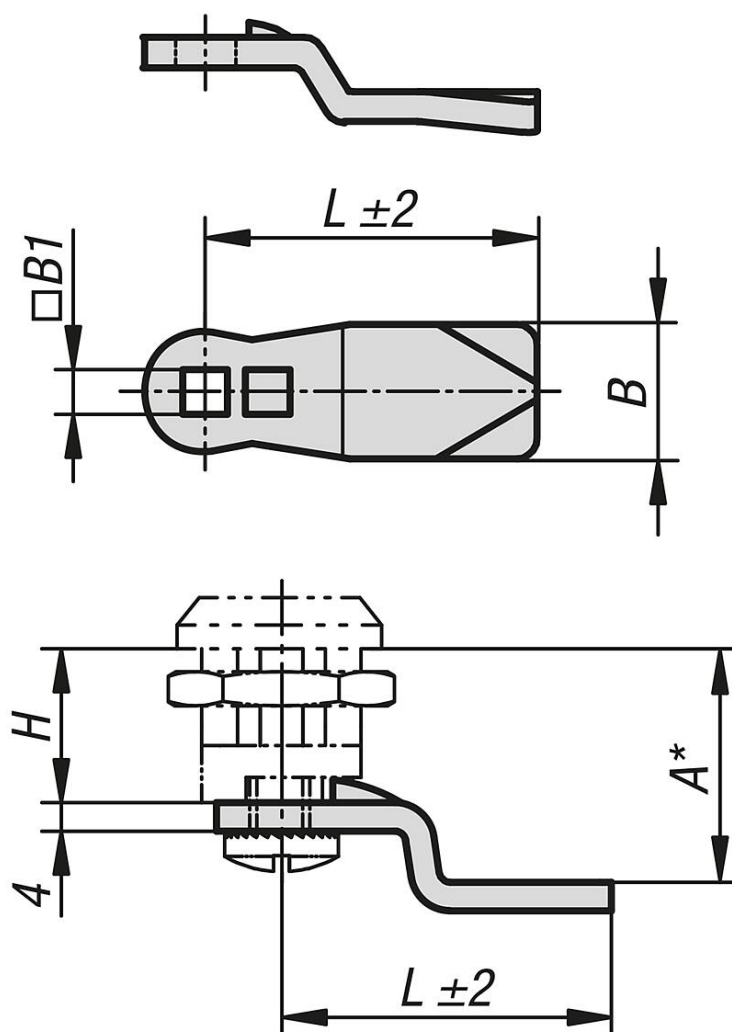

Overview of items

Tongue steel, with stop

Overview of items

Tongue steel, with stop

Order No.	Version 1	Version 2	A for housing length H=18	A for housing length H=30	A for housing length H=50	B	B1	L	Suitable for
K2218.13506	with stop	offset upwards	6	18	38	19	8,1	35	-
K2218.13508	with stop	offset upwards	8	20	40	19	8,1	35	-
K2218.13510	with stop	offset upwards	10	22	42	19	8,1	35	-
K2218.13513	with stop	offset upwards	13	25	45	19	8,1	35	-
K2218.13514	with stop	offset upwards	14	26	46	19	8,1	35	-
K2218.13516	with stop	offset upwards	16	28	48	19	8,1	35	-
K2218.13518	with stop	straight	18	30	50	19	8,1	35	-
K2218.13520	with stop	offset downwards	20	32	52	19	8,1	35	-
K2218.13522	with stop	offset downwards	22	34	54	19	8,1	35	-
K2218.13524	with stop	offset downwards	24	36	56	19	8,1	35	-
K2218.13526	with stop	offset downwards	26	38	58	19	8,1	35	-
K2218.13528	with stop	offset downwards	28	40	60	19	8,1	35	-
K2218.14504	with stop	offset upwards	4	16	36	19	8,1	45	-
K2218.14506	with stop	offset upwards	6	18	38	19	8,1	45	-
K2218.14508	with stop	offset upwards	8	20	40	19	8,1	45	-
K2218.14510	with stop	offset upwards	10	22	42	19	8,1	45	-
K2218.14513	with stop	offset upwards	13	25	45	19	8,1	45	-
K2218.14514	with stop	offset upwards	14	26	46	19	8,1	45	-
K2218.14516	with stop	offset upwards	16	28	48	19	8,1	45	-
K2218.14518	with stop	straight	18	30	50	19	8,1	45	-
K2218.14520	with stop	offset downwards	20	32	52	19	8,1	45	-
K2218.14522	with stop	offset downwards	22	34	54	19	8,1	45	-
K2218.14524	with stop	offset downwards	24	36	56	19	8,1	45	-
K2218.14526	with stop	offset downwards	26	38	58	19	8,1	45	-
K2218.14528	with stop	offset downwards	28	40	60	19	8,1	45	-
K2218.14530	with stop	offset downwards	30	42	62	19	8,1	45	-
K2218.14532	with stop	offset downwards	32	44	64	19	8,1	45	-
K2218.14534	with stop	offset downwards	34	46	66	19	8,1	45	-
K2218.14536	with stop	offset downwards	36	48	68	19	8,1	45	-
K2218.14538	with stop	offset downwards	38	50	70	19	8,1	45	-
K2218.14540	with stop	offset downwards	40	52	72	19	8,1	45	-
K2218.14542	with stop	offset downwards	42	54	74	19	8,1	45	-