

Poignées de manutention en Inox, ovales

Description de l'article/illustrations du produit




Description

Matière :
Inox 1.4301.

Finition :
Surface : polie, satinée.

Montage :
Fixation par l'arrière.

Dessins

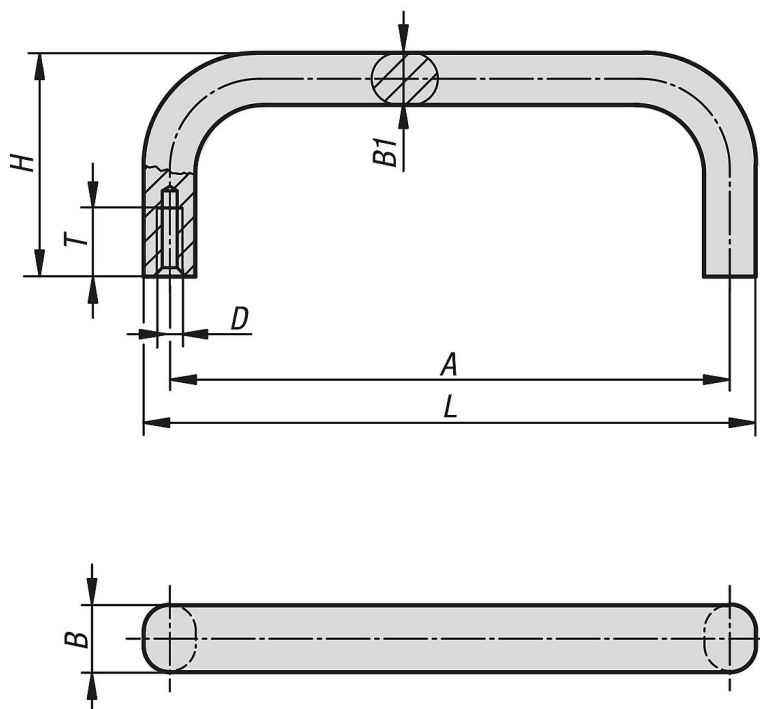

Aperçu des articles

Référence	A	B	B1	D	H	L	T	Charge N
K1086.1000805	100	12	8	M5	39	108	10	1000
K1086.1200805	120	12	8	M5	39	128	10	1000
K1086.1001005	100	15	10	M5	39	110	10	1000
K1086.1501005	150	15	10	M5	39	160	10	1000
K1086.1801005	180	15	10	M5	39	190	10	1000

