

## Pull handles arched, entirely plastic

### Item description/product images

---



### Description

**Material:**

Glass-bead reinforced thermoplastic.

**Version:**

matt black.

**Note:**

Ergonomic and functional pull handles with temperature resistance of -50 °C to +130 °C.

Supplied with DIN 912 electro zinc-plated socket head screws, DIN 934 nuts, DIN 125 electro zinc-plated washers and caps.

The versions K0193.110006 and K0193.210006 are supplied without caps.

**Assembly:**

From the front.

**Drawing reference:**

Form A: with base plate


Form B: without base plate

1) cover cap

2) base plate

# Pull handles arched, entirely plastic

## Drawings

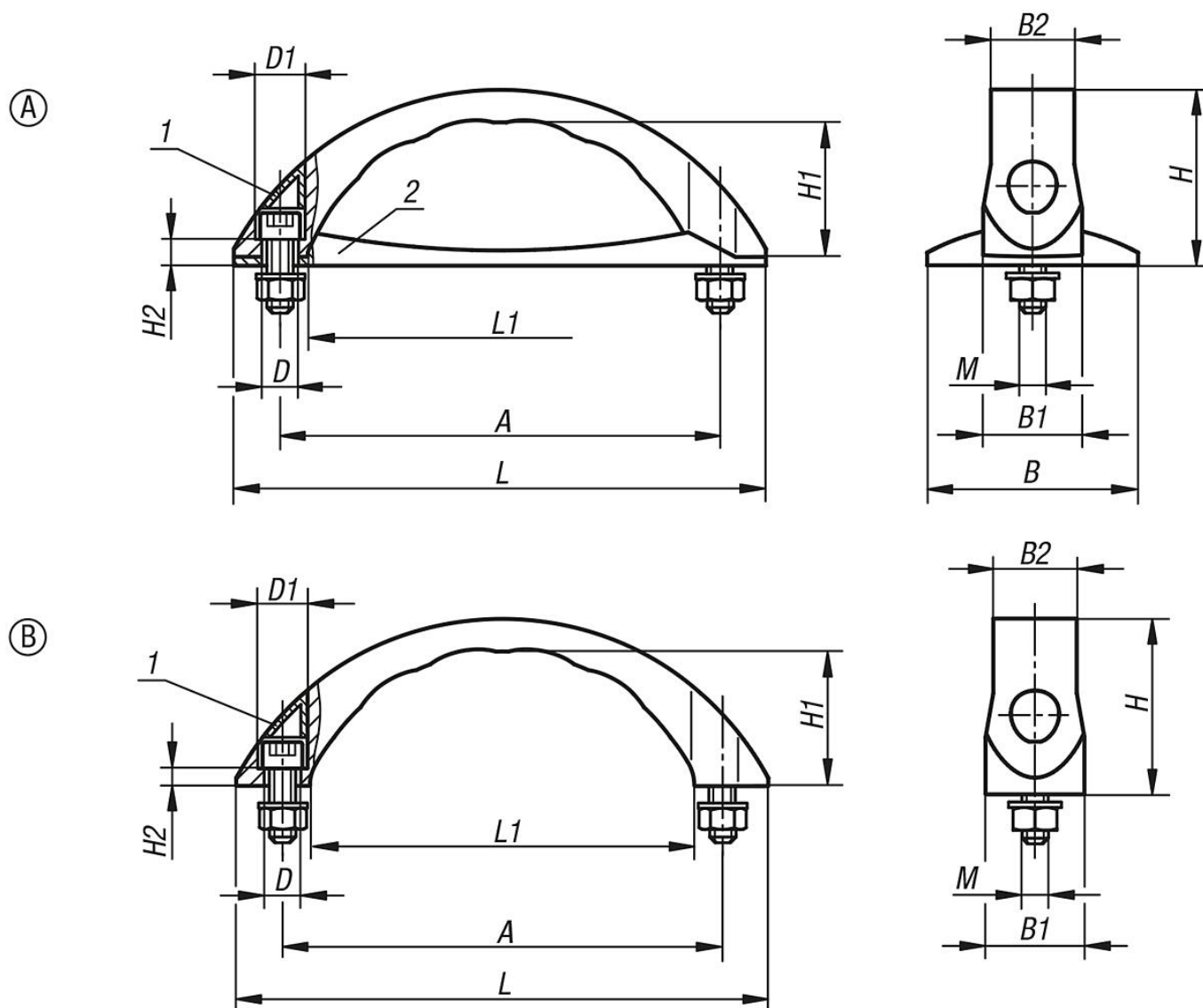

## Overview of items

### Pull handles, arch

| Order No.    | Form | Type               | Version 1          | A   | B  | B1 | B2 | D   | D1 | H  | H1 | H2  | L   | L1  | M     | Load capacity N |
|--------------|------|--------------------|--------------------|-----|----|----|----|-----|----|----|----|-----|-----|-----|-------|-----------------|
| K0193.110006 | A    | with base plate    | with base plate    | 100 | 48 | 23 | 19 | 7   | 11 | 40 | 29 | 6   | 121 | 84  | M6x25 | 600             |
| K0193.112006 | A    | with base plate    | with base plate    | 120 | 57 | 28 | 23 | 7   | 12 | 52 | 36 | 7   | 152 | 104 | M6x25 | 600             |
| K0193.114008 | A    | with base plate    | with base plate    | 140 | 62 | 31 | 25 | 9,5 | 16 | 56 | 37 | 7,5 | 177 | 122 | M8x30 | 600             |
| K0193.210006 | B    | without base plate | without base plate | 100 | -  | 23 | 19 | 7   | 11 | 38 | 31 | 4   | 121 | 84  | M6x25 | 600             |
| K0193.212006 | B    | without base plate | without base plate | 120 | -  | 28 | 23 | 7   | 12 | 50 | 38 | 5   | 152 | 104 | M6x25 | 600             |
| K0193.214008 | B    | without base plate | without base plate | 140 | -  | 31 | 25 | 9,5 | 16 | 54 | 39 | 5,5 | 177 | 122 | M8x30 | 600             |

## **Pull handles arched, entirely plastic**

Overview of items

---