

Parallel keys DIN 6885 A

Item description/product images



Description


Material:

Steel 1.1192 or stainless steel 1.4571.


Version:

Bright.

Application example:

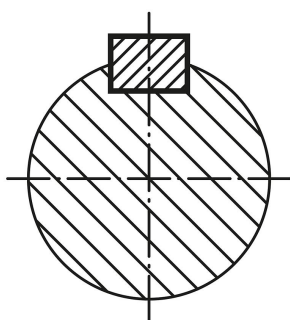

Drawings

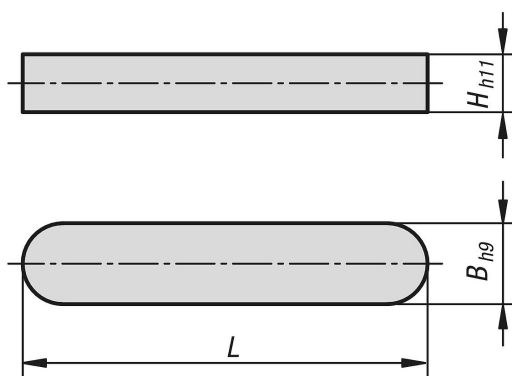

Overview of items

Parallel keys DIN 6885 A

| Order No. | Main material | B | H | L = length |
|-------------|---------------|---|---|------------|
| K0696.03X8 | steel | 3 | 3 | 8 |
| K0696.03X10 | steel | 3 | 3 | 10 |
| K0696.03X12 | steel | 3 | 3 | 12 |
| K0696.03X14 | steel | 3 | 3 | 14 |
| K0696.03X16 | steel | 3 | 3 | 16 |
| K0696.03X18 | steel | 3 | 3 | 18 |
| K0696.03X20 | steel | 3 | 3 | 20 |
| K0696.03X22 | steel | 3 | 3 | 22 |
| K0696.03X25 | steel | 3 | 3 | 25 |

Parallel keys DIN 6885 A

Overview of items

| Order No. | Main material | B | H | L = length |
|-------------|---------------|----|---|------------|
| K0696.03X28 | steel | 3 | 3 | 28 |
| K0696.04X8 | steel | 4 | 4 | 8 |
| K0696.04X10 | steel | 4 | 4 | 10 |
| K0696.04X12 | steel | 4 | 4 | 12 |
| K0696.04X14 | steel | 4 | 4 | 14 |
| K0696.04X16 | steel | 4 | 4 | 16 |
| K0696.04X18 | steel | 4 | 4 | 18 |
| K0696.04X20 | steel | 4 | 4 | 20 |
| K0696.04X22 | steel | 4 | 4 | 22 |
| K0696.04X25 | steel | 4 | 4 | 25 |
| K0696.04X28 | steel | 4 | 4 | 28 |
| K0696.05X12 | steel | 5 | 5 | 12 |
| K0696.05X14 | steel | 5 | 5 | 14 |
| K0696.05X16 | steel | 5 | 5 | 16 |
| K0696.05X18 | steel | 5 | 5 | 18 |
| K0696.05X20 | steel | 5 | 5 | 20 |
| K0696.05X22 | steel | 5 | 5 | 22 |
| K0696.05X25 | steel | 5 | 5 | 25 |
| K0696.05X28 | steel | 5 | 5 | 28 |
| K0696.05X32 | steel | 5 | 5 | 32 |
| K0696.05X36 | steel | 5 | 5 | 36 |
| K0696.05X40 | steel | 5 | 5 | 40 |
| K0696.06X12 | steel | 6 | 6 | 12 |
| K0696.06X14 | steel | 6 | 6 | 14 |
| K0696.06X16 | steel | 6 | 6 | 16 |
| K0696.06X18 | steel | 6 | 6 | 18 |
| K0696.06X20 | steel | 6 | 6 | 20 |
| K0696.06X22 | steel | 6 | 6 | 22 |
| K0696.06X25 | steel | 6 | 6 | 25 |
| K0696.06X28 | steel | 6 | 6 | 28 |
| K0696.06X32 | steel | 6 | 6 | 32 |
| K0696.06X36 | steel | 6 | 6 | 36 |
| K0696.06X40 | steel | 6 | 6 | 40 |
| K0696.06X45 | steel | 6 | 6 | 45 |
| K0696.08X14 | steel | 8 | 7 | 14 |
| K0696.08X16 | steel | 8 | 7 | 16 |
| K0696.08X18 | steel | 8 | 7 | 18 |
| K0696.08X20 | steel | 8 | 7 | 20 |
| K0696.08X22 | steel | 8 | 7 | 22 |
| K0696.08X25 | steel | 8 | 7 | 25 |
| K0696.08X28 | steel | 8 | 7 | 28 |
| K0696.08X32 | steel | 8 | 7 | 32 |
| K0696.08X36 | steel | 8 | 7 | 36 |
| K0696.08X40 | steel | 8 | 7 | 40 |
| K0696.08X45 | steel | 8 | 7 | 45 |
| K0696.08X50 | steel | 8 | 7 | 50 |
| K0696.08X70 | steel | 8 | 7 | 70 |
| K0696.10X22 | steel | 10 | 8 | 22 |
| K0696.10X25 | steel | 10 | 8 | 25 |
| K0696.10X28 | steel | 10 | 8 | 28 |
| K0696.10X32 | steel | 10 | 8 | 32 |
| K0696.10X36 | steel | 10 | 8 | 36 |
| K0696.10X40 | steel | 10 | 8 | 40 |
| K0696.10X45 | steel | 10 | 8 | 45 |
| K0696.10X50 | steel | 10 | 8 | 50 |
| K0696.10X56 | steel | 10 | 8 | 56 |
| K0696.10X70 | steel | 10 | 8 | 70 |
| K0696.10X80 | steel | 10 | 8 | 80 |
| K0696.12X25 | steel | 12 | 8 | 25 |
| K0696.12X28 | steel | 12 | 8 | 28 |
| K0696.12X32 | steel | 12 | 8 | 32 |
| K0696.12X36 | steel | 12 | 8 | 36 |

Parallel keys DIN 6885 A

Overview of items

| Order No. | Main material | B | H | L = length |
|--------------|-----------------|----|----|------------|
| K0696.12X40 | steel | 12 | 8 | 40 |
| K0696.12X45 | steel | 12 | 8 | 45 |
| K0696.12X50 | steel | 12 | 8 | 50 |
| K0696.12X56 | steel | 12 | 8 | 56 |
| K0696.12X70 | steel | 12 | 8 | 70 |
| K0696.12X80 | steel | 12 | 8 | 80 |
| K0696.14X25 | steel | 14 | 9 | 25 |
| K0696.14X28 | steel | 14 | 9 | 28 |
| K0696.14X32 | steel | 14 | 9 | 32 |
| K0696.14X36 | steel | 14 | 9 | 36 |
| K0696.14X40 | steel | 14 | 9 | 40 |
| K0696.14X45 | steel | 14 | 9 | 45 |
| K0696.14X50 | steel | 14 | 9 | 50 |
| K0696.14X56 | steel | 14 | 9 | 56 |
| K0696.14X70 | steel | 14 | 9 | 70 |
| K0696.14X80 | steel | 14 | 9 | 80 |
| K0696.16X50 | steel | 16 | 10 | 50 |
| K0696.16X56 | steel | 16 | 10 | 56 |
| K0696.16X63 | steel | 16 | 10 | 63 |
| K0696.16X70 | steel | 16 | 10 | 70 |
| K0696.16X80 | steel | 16 | 10 | 80 |
| K0696.16X90 | steel | 16 | 10 | 90 |
| K0696.16X100 | steel | 16 | 10 | 100 |
| K0696.103X10 | stainless steel | 3 | 3 | 10 |
| K0696.103X12 | stainless steel | 3 | 3 | 12 |
| K0696.103X16 | stainless steel | 3 | 3 | 16 |
| K0696.103X20 | stainless steel | 3 | 3 | 20 |
| K0696.104X10 | stainless steel | 4 | 4 | 10 |
| K0696.104X12 | stainless steel | 4 | 4 | 12 |
| K0696.104X14 | stainless steel | 4 | 4 | 14 |
| K0696.104X16 | stainless steel | 4 | 4 | 16 |
| K0696.104X18 | stainless steel | 4 | 4 | 18 |
| K0696.104X20 | stainless steel | 4 | 4 | 20 |
| K0696.104X22 | stainless steel | 4 | 4 | 22 |
| K0696.105X12 | stainless steel | 5 | 5 | 12 |
| K0696.105X14 | stainless steel | 5 | 5 | 14 |
| K0696.105X16 | stainless steel | 5 | 5 | 16 |
| K0696.105X18 | stainless steel | 5 | 5 | 18 |
| K0696.105X20 | stainless steel | 5 | 5 | 20 |
| K0696.105X22 | stainless steel | 5 | 5 | 22 |
| K0696.105X25 | stainless steel | 5 | 5 | 25 |
| K0696.105X28 | stainless steel | 5 | 5 | 28 |
| K0696.105X36 | stainless steel | 5 | 5 | 36 |
| K0696.105X40 | stainless steel | 5 | 5 | 40 |
| K0696.106X12 | stainless steel | 6 | 6 | 12 |
| K0696.106X14 | stainless steel | 6 | 6 | 14 |
| K0696.106X16 | stainless steel | 6 | 6 | 16 |
| K0696.106X18 | stainless steel | 6 | 6 | 18 |
| K0696.106X20 | stainless steel | 6 | 6 | 20 |
| K0696.106X22 | stainless steel | 6 | 6 | 22 |
| K0696.106X25 | stainless steel | 6 | 6 | 25 |
| K0696.106X28 | stainless steel | 6 | 6 | 28 |
| K0696.106X32 | stainless steel | 6 | 6 | 32 |
| K0696.106X36 | stainless steel | 6 | 6 | 36 |
| K0696.106X40 | stainless steel | 6 | 6 | 40 |
| K0696.108X16 | stainless steel | 8 | 7 | 16 |
| K0696.108X18 | stainless steel | 8 | 7 | 18 |
| K0696.108X20 | stainless steel | 8 | 7 | 20 |
| K0696.108X22 | stainless steel | 8 | 7 | 22 |
| K0696.108X25 | stainless steel | 8 | 7 | 25 |
| K0696.108X28 | stainless steel | 8 | 7 | 28 |
| K0696.108X32 | stainless steel | 8 | 7 | 32 |

Parallel keys DIN 6885 A

Overview of items

| Order No. | Main material | B | H | L = length |
|---------------|-----------------|----|----|------------|
| K0696.108X36 | stainless steel | 8 | 7 | 36 |
| K0696.108X40 | stainless steel | 8 | 7 | 40 |
| K0696.108X45 | stainless steel | 8 | 7 | 45 |
| K0696.108X50 | stainless steel | 8 | 7 | 50 |
| K0696.108X70 | stainless steel | 8 | 7 | 70 |
| K0696.110X22 | stainless steel | 10 | 8 | 22 |
| K0696.110X25 | stainless steel | 10 | 8 | 25 |
| K0696.110X28 | stainless steel | 10 | 8 | 28 |
| K0696.110X32 | stainless steel | 10 | 8 | 32 |
| K0696.110X36 | stainless steel | 10 | 8 | 36 |
| K0696.110X40 | stainless steel | 10 | 8 | 40 |
| K0696.110X45 | stainless steel | 10 | 8 | 45 |
| K0696.110X50 | stainless steel | 10 | 8 | 50 |
| K0696.110X56 | stainless steel | 10 | 8 | 56 |
| K0696.110X70 | stainless steel | 10 | 8 | 70 |
| K0696.110X80 | stainless steel | 10 | 8 | 80 |
| K0696.112X28 | stainless steel | 12 | 8 | 28 |
| K0696.112X32 | stainless steel | 12 | 8 | 32 |
| K0696.112X36 | stainless steel | 12 | 8 | 36 |
| K0696.112X40 | stainless steel | 12 | 8 | 40 |
| K0696.112X45 | stainless steel | 12 | 8 | 45 |
| K0696.112X50 | stainless steel | 12 | 8 | 50 |
| K0696.112X56 | stainless steel | 12 | 8 | 56 |
| K0696.112X70 | stainless steel | 12 | 8 | 70 |
| K0696.112X80 | stainless steel | 12 | 8 | 80 |
| K0696.114X32 | stainless steel | 14 | 9 | 32 |
| K0696.114X40 | stainless steel | 14 | 9 | 40 |
| K0696.114X45 | stainless steel | 14 | 9 | 45 |
| K0696.114X50 | stainless steel | 14 | 9 | 50 |
| K0696.114X56 | stainless steel | 14 | 9 | 56 |
| K0696.114X70 | stainless steel | 14 | 9 | 70 |
| K0696.114X80 | stainless steel | 14 | 9 | 80 |
| K0696.116X50 | stainless steel | 16 | 10 | 50 |
| K0696.116X63 | stainless steel | 16 | 10 | 63 |
| K0696.116X70 | stainless steel | 16 | 10 | 70 |
| K0696.116X80 | stainless steel | 16 | 10 | 80 |
| K0696.116X90 | stainless steel | 16 | 10 | 90 |
| K0696.116X100 | stainless steel | 16 | 10 | 100 |