

Tongue stainless, without stop

Item description/product images



Description

Material:

Stainless steel 1.4301.

Version:

Bright.


Note:

*A in mm by housing length H=26.1 mm.

Accessory:

Quarter-turn lock zinc, for fire services, DIN 14925 K2219.

Drawings

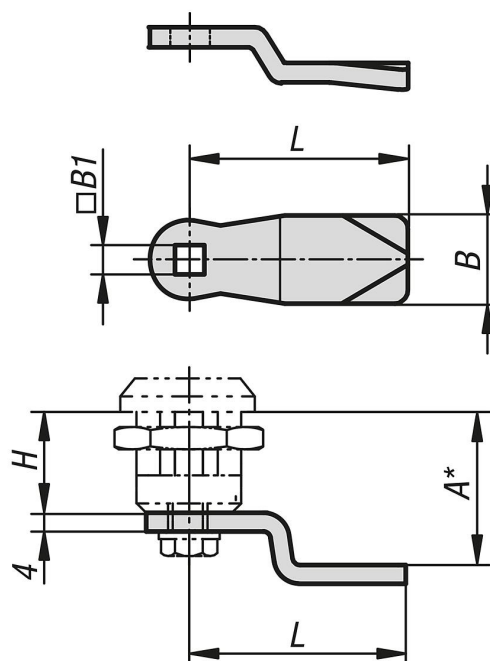

Overview of items

Tongue stainless, without stop

Order No.	Version 1	Version 2	A at H=26.1	B	B1	L	Suitable for
K2221.145X521	without stop	offset downwards	52,1	19,5	8,1	45	-
K2221.145X501	without stop	offset downwards	50,1	19,5	8,1	45	-
K2221.145X481	without stop	offset downwards	48,1	19,5	8,1	45	-
K2221.145X461	without stop	offset downwards	46,1	19,5	8,1	45	-
K2221.145X441	without stop	offset downwards	44,1	19,5	8,1	45	-
K2221.145X421	without stop	offset downwards	42,1	19,5	8,1	45	-
K2221.145X401	without stop	offset downwards	40,1	19,5	8,1	45	-
K2221.145X381	without stop	offset downwards	38,1	19,5	8,1	45	-
K2221.145X361	without stop	offset downwards	36,1	19,5	8,1	45	-
K2221.145X341	without stop	offset downwards	34,1	19,5	8,1	45	-
K2221.145X321	without stop	offset downwards	32,1	19,5	8,1	45	-
K2221.145X301	without stop	offset downwards	30,1	19,5	8,1	45	-

Tongue stainless, without stop

Overview of items

Order No.	Version 1	Version 2	A at H=26.1	B	B1	L	Suitable for
K2221.145X281	without stop	offset downwards	28,1	19,5	8,1	45	-
K2221.145X261	without stop	straight	26,1	19,5	8,1	45	-
K2221.145X241	without stop	offset upwards	24,1	19,5	8,1	45	-
K2221.145X221	without stop	offset upwards	22,1	19,5	8,1	45	-
K2221.145X201	without stop	offset upwards	20,1	19,5	8,1	45	-
K2221.145X181	without stop	offset upwards	18,1	19,5	8,1	45	-
K2221.145X161	without stop	offset upwards	16,1	19,5	8,1	45	-
K2221.145X141	without stop	offset upwards	14,1	19,5	8,1	45	-
K2221.145X121	without stop	offset upwards	12,1	19,5	8,1	45	-