


# Knurled knobs Form C, with standard scale

## Item description/product images

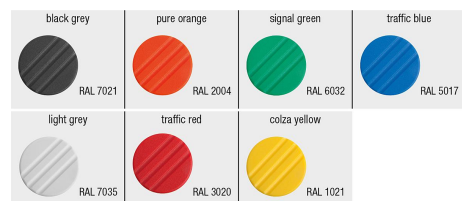

## Description

### Material:

Thermoplastic, black grey.  
Bush steel.

### Version:

Bush blue passivated

### Note:

Available without graduations, with one scale line or with 20 graduations and 10 digits.

Δ Add the desired cap colour here. No colour code is required for black grey caps.

### On request:

Special graduations.

### Drawing reference:


Form A: without graduations

Form B: with one scale line

Form C: with standard graduations

1) Set screw for locking (by Form C between numbers 5 and 6)

## Drawings

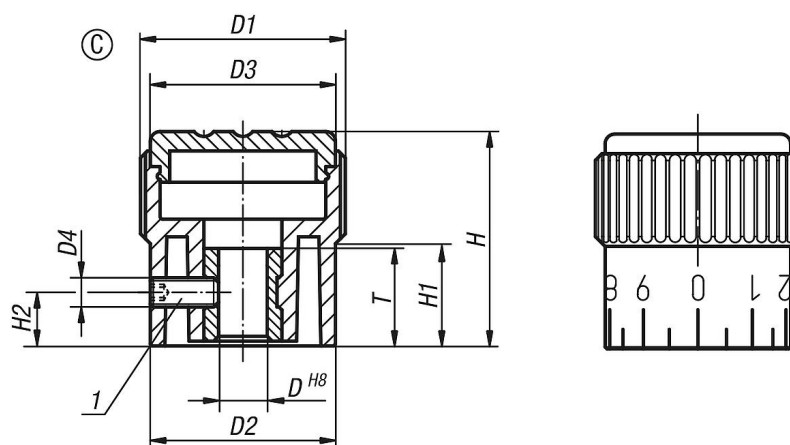

## Overview of items

Order No.	Form	Colour Cap	D	D1	D2	D3	D4	H	H1	H2	T
K0248.3105	C	black grey RAL 7021	5	21	19	19	M3	22	10,5	5	10
K0248.31051	C	orange RAL 2004	5	21	19	19	M3	22	10,5	5	10
K0248.31052	C	signal green RAL6032	5	21	19	19	M3	22	10,5	5	10
K0248.31053	C	blue RAL5017	5	21	19	19	M3	22	10,5	5	10
K0248.31055	C	light grey RAL 7035	5	21	19	19	M3	22	10,5	5	10
K0248.31056	C	traffic red RAL 3020	5	21	19	19	M3	22	10,5	5	10
K0248.31057	C	colza yellow RAL 1021	5	21	19	19	M3	22	10,5	5	10
K0248.3206	C	black grey RAL 7021	6	26	23	23	M3	26	12	6	10
K0248.32061	C	orange RAL 2004	6	26	23	23	M3	26	12	6	10
K0248.32062	C	signal green RAL6032	6	26	23	23	M3	26	12	6	10

## Knurled knobs Form C, with standard scale

### Overview of items

Order No.	Form	Colour Cap	D	D1	D2	D3	D4	H	H1	H2	T
K0248.32063	C	blue RAL5017	6	26	23	23	M3	26	12	6	10
K0248.32065	C	light grey RAL 7035	6	26	23	23	M3	26	12	6	10
K0248.32066	C	traffic red RAL 3020	6	26	23	23	M3	26	12	6	10
K0248.32067	C	colza yellow RAL 1021	6	26	23	23	M3	26	12	6	10
K0248.3308	C	black grey RAL 7021	8	34	31	31	M4	36	17,5	7	14
K0248.33081	C	orange RAL 2004	8	34	31	31	M4	36	17,5	7	14
K0248.33082	C	signal green RAL6032	8	34	31	31	M4	36	17,5	7	14
K0248.33083	C	blue RAL5017	8	34	31	31	M4	36	17,5	7	14
K0248.33085	C	light grey RAL 7035	8	34	31	31	M4	36	17,5	7	14
K0248.33086	C	traffic red RAL 3020	8	34	31	31	M4	36	17,5	7	14
K0248.33087	C	colza yellow RAL 1021	8	34	31	31	M4	36	17,5	7	14