

## Socket head screws full thread, DIN 912

### Item description/product images



### Description

#### Material:

Steel, stainless steel A2 or stainless steel A4.


#### Version:

Steel grade 8.8, bright (blackened) or electro zinc-plated.

Stainless steel A2-70, bright

Stainless steel A4-70, bright

### Drawings

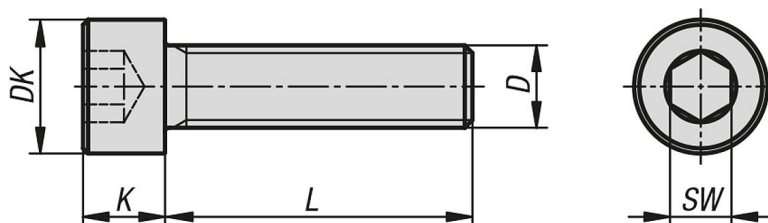

### Overview of items

Order No.	Main material	Grade	Surface finish body	D	L	DK	K	SW
K1159.05X40	steel	8.8	bright (black)	M5	40	8,5	5	4
K1159.05X50	steel	8.8	bright (black)	M5	50	8,5	5	4
K1159.05X60	steel	8.8	bright (black)	M5	60	8,5	5	4
K1159.05X80	steel	8.8	bright (black)	M5	80	8,5	5	4
K1159.06X40	steel	8.8	bright (black)	M6	40	10	6	5
K1159.06X50	steel	8.8	bright (black)	M6	50	10	6	5
K1159.06X60	steel	8.8	bright (black)	M6	60	10	6	5
K1159.06X70	steel	8.8	bright (black)	M6	70	10	6	5
K1159.06X90	steel	8.8	bright (black)	M6	90	10	6	5
K1159.06X100	steel	8.8	bright (black)	M6	100	10	6	5
K1159.08X50	steel	8.8	bright (black)	M8	50	13	8	6
K1159.08X60	steel	8.8	bright (black)	M8	60	13	8	6
K1159.08X70	steel	8.8	bright (black)	M8	70	13	8	6
K1159.08X80	steel	8.8	bright (black)	M8	80	13	8	6
K1159.08X90	steel	8.8	bright (black)	M8	90	13	8	6
K1159.10X50	steel	8.8	bright (black)	M10	50	16	10	8
K1159.10X60	steel	8.8	bright (black)	M10	60	16	10	8
K1159.10X70	steel	8.8	bright (black)	M10	70	16	10	8
K1159.10X80	steel	8.8	bright (black)	M10	80	16	10	8
K1159.10X90	steel	8.8	bright (black)	M10	90	16	10	8
K1159.10X100	steel	8.8	bright (black)	M10	100	16	10	8
K1159.12X80	steel	8.8	bright (black)	M12	80	18	12	10
K1159.12X90	steel	8.8	bright (black)	M12	90	18	12	10
K1159.12X100	steel	8.8	bright (black)	M12	100	18	12	10
K1159.405X40	steel	8.8	galvanised	M5	40	8,5	5	4
K1159.405X70	steel	8.8	galvanised	M5	70	8,5	5	4
K1159.405X80	steel	8.8	galvanised	M5	80	8,5	5	4
K1159.406X40	steel	8.8	galvanised	M6	40	10	6	5
K1159.406X50	steel	8.8	galvanised	M6	50	10	6	5
K1159.406X60	steel	8.8	galvanised	M6	60	10	6	5
K1159.406X70	steel	8.8	galvanised	M6	70	10	6	5
K1159.406X80	steel	8.8	galvanised	M6	80	10	6	5

## Socket head screws full thread, DIN 912

### Overview of items

Order No.	Main material	Grade	Surface finish body	D	L	DK	K	SW
K1159.406X90	steel	8.8	galvanised	M6	90	10	6	5
K1159.406X100	steel	8.8	galvanised	M6	100	10	6	5
K1159.408X50	steel	8.8	galvanised	M8	50	13	8	6
K1159.408X60	steel	8.8	galvanised	M8	60	13	8	6
K1159.408X70	steel	8.8	galvanised	M8	70	13	8	6
K1159.408X80	steel	8.8	galvanised	M8	80	13	8	6
K1159.408X90	steel	8.8	galvanised	M8	90	13	8	6
K1159.408X100	steel	8.8	galvanised	M8	100	13	8	6
K1159.410X50	steel	8.8	galvanised	M10	50	16	10	8
K1159.410X60	steel	8.8	galvanised	M10	60	16	10	8
K1159.410X70	steel	8.8	galvanised	M10	70	16	10	8
K1159.410X80	steel	8.8	galvanised	M10	80	16	10	8
K1159.410X90	steel	8.8	galvanised	M10	90	16	10	8
K1159.410X100	steel	8.8	galvanised	M10	100	16	10	8
K1159.412X70	steel	8.8	galvanised	M12	70	18	12	10
K1159.412X80	steel	8.8	galvanised	M12	80	18	12	10
K1159.412X90	steel	8.8	galvanised	M12	90	18	12	10
K1159.412X100	steel	8.8	galvanised	M12	100	18	12	10
K1159.105X40	stainless steel A2	70	bright	M5	40	8,5	5	4
K1159.105X70	stainless steel A2	70	bright	M5	70	8,5	5	4
K1159.106X40	stainless steel A2	70	bright	M6	40	10	6	5
K1159.106X50	stainless steel A2	70	bright	M6	50	10	6	5
K1159.106X60	stainless steel A2	70	bright	M6	60	10	6	5
K1159.106X70	stainless steel A2	70	bright	M6	70	10	6	5
K1159.106X80	stainless steel A2	70	bright	M6	80	10	6	5
K1159.106X90	stainless steel A2	70	bright	M6	90	10	6	5
K1159.106X100	stainless steel A2	70	bright	M6	100	10	6	5
K1159.108X50	stainless steel A2	70	bright	M8	50	13	8	6
K1159.108X60	stainless steel A2	70	bright	M8	60	13	8	6
K1159.108X70	stainless steel A2	70	bright	M8	70	13	8	6
K1159.108X80	stainless steel A2	70	bright	M8	80	13	8	6
K1159.108X90	stainless steel A2	70	bright	M8	90	13	8	6
K1159.108X100	stainless steel A2	70	bright	M8	100	13	8	6
K1159.110X50	stainless steel A2	70	bright	M10	50	16	10	8
K1159.110X60	stainless steel A2	70	bright	M10	60	16	10	8
K1159.110X70	stainless steel A2	70	bright	M10	70	16	10	8
K1159.110X80	stainless steel A2	70	bright	M10	80	16	10	8
K1159.110X90	stainless steel A2	70	bright	M10	90	16	10	8
K1159.110X100	stainless steel A2	70	bright	M10	100	16	10	8
K1159.112X70	stainless steel A2	70	bright	M12	70	18	12	10
K1159.112X80	stainless steel A2	70	bright	M12	80	18	12	10
K1159.112X90	stainless steel A2	70	bright	M12	90	18	12	10
K1159.112X100	stainless steel A2	70	bright	M12	100	18	12	10
K1159.605X40	stainless steel A4	70	bright	M5	40	8,5	5	4
K1159.605X70	stainless steel A4	70	bright	M5	70	8,5	5	4
K1159.605X80	stainless steel A4	70	bright	M5	80	8,5	5	4
K1159.606X40	stainless steel A4	70	bright	M6	40	10	6	5
K1159.606X50	stainless steel A4	70	bright	M6	50	10	6	5
K1159.606X60	stainless steel A4	70	bright	M6	60	10	6	5
K1159.606X70	stainless steel A4	70	bright	M6	70	10	6	5
K1159.606X80	stainless steel A4	70	bright	M6	80	10	6	5
K1159.606X90	stainless steel A4	70	bright	M6	90	10	6	5
K1159.606X100	stainless steel A4	70	bright	M6	100	10	6	5
K1159.608X50	stainless steel A4	70	bright	M8	50	13	8	6
K1159.608X60	stainless steel A4	70	bright	M8	60	13	8	6
K1159.608X70	stainless steel A4	70	bright	M8	70	13	8	6
K1159.608X80	stainless steel A4	70	bright	M8	80	13	8	6
K1159.608X90	stainless steel A4	70	bright	M8	90	13	8	6
K1159.608X100	stainless steel A4	70	bright	M8	100	13	8	6
K1159.610X50	stainless steel A4	70	bright	M10	50	16	10	8
K1159.610X60	stainless steel A4	70	bright	M10	60	16	10	8
K1159.610X70	stainless steel A4	70	bright	M10	70	16	10	8

## Socket head screws full thread, DIN 912

### Overview of items

Order No.	Main material	Grade	Surface finish body	D	L	DK	K	SW
K1159.610X80	stainless steel A4	70	bright	M10	80	16	10	8
K1159.610X90	stainless steel A4	70	bright	M10	90	16	10	8
K1159.610X100	stainless steel A4	70	bright	M10	100	16	10	8
K1159.612X80	stainless steel A4	70	bright	M12	80	18	12	10
K1159.612X100	stainless steel A4	70	bright	M12	100	18	12	10