


## Scale tape, steel self-adhesive

### Item description/product images

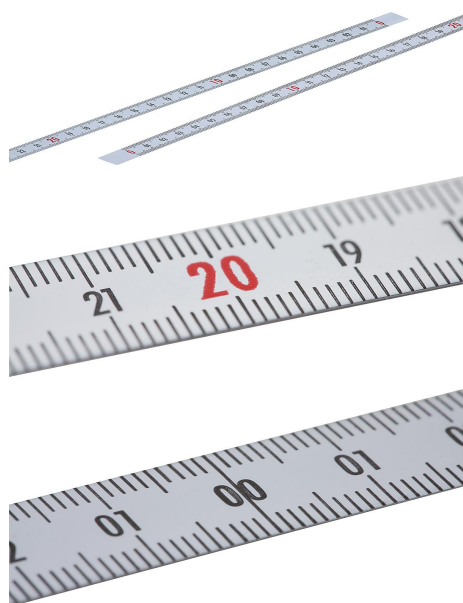

### Description

#### Material:

Steel.

#### Version:

Painted white.

#### Note:


Scale tapes with mm graduations on top and bottom edge in black and consecutive centimetre numbering. Decimal numbers in red (under 1 m lengths and with centre zero black only).

The scale tapes are self-adhesive with a peel-away foil film on the back. The film must be removed before use.

#### Application:

The scale tapes can be used where a precise measurement is required. They are used on machines, work tables and workbenches.

### Drawings

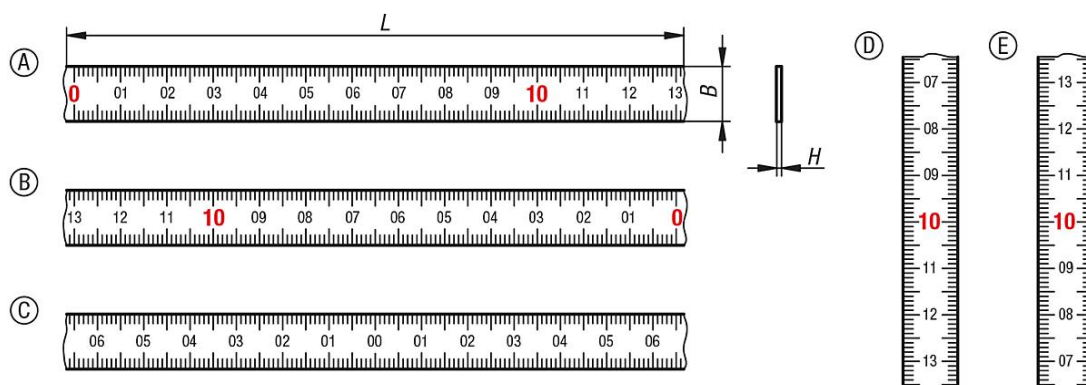

### Overview of items

#### Scale tapes, steel, self-adhesive

Order No.	Version 1	Form	Zero point	Division	Graduations	B	H	L
K1301.00021010X0300	horizontal	A	left	1 mm	both sides	10	0,5	300
K1301.00021010X0500	horizontal	A	left	1 mm	both sides	10	0,5	500
K1301.00021010X1000	horizontal	A	left	1 mm	both sides	10	0,5	1000
K1301.00021010X2000	horizontal	A	left	1 mm	both sides	10	0,5	2000
K1301.00021010X3000	horizontal	A	left	1 mm	both sides	10	0,5	3000
K1301.00021010X5000	horizontal	A	left	1 mm	both sides	10	0,5	5000
K1301.00021010X6000	horizontal	A	left	1 mm	both sides	10	0,5	6000
K1301.00021013X0300	horizontal	A	left	1 mm	both sides	13	0,5	300
K1301.00021013X0500	horizontal	A	left	1 mm	both sides	13	0,5	500
K1301.00021013X1000	horizontal	A	left	1 mm	both sides	13	0,5	1000
K1301.00021013X2000	horizontal	A	left	1 mm	both sides	13	0,5	2000
K1301.00021013X3000	horizontal	A	left	1 mm	both sides	13	0,5	3000
K1301.00021013X5000	horizontal	A	left	1 mm	both sides	13	0,5	5000
K1301.00021013X6000	horizontal	A	left	1 mm	both sides	13	0,5	6000
K1301.00221010X0300	horizontal	B	right	1 mm	both sides	10	0,5	300
K1301.00221010X0500	horizontal	B	right	1 mm	both sides	10	0,5	500

## Scale tape, steel self-adhesive

### Overview of items

Order No.	Version 1	Form	Zero point	Division	Graduations	B	H	L
K1301.00221010X1000	horizontal	B	right	1 mm	both sides	10	0,5	1000
K1301.00221010X2000	horizontal	B	right	1 mm	both sides	10	0,5	2000
K1301.00221010X3000	horizontal	B	right	1 mm	both sides	10	0,5	3000
K1301.00221010X5000	horizontal	B	right	1 mm	both sides	10	0,5	5000
K1301.00221010X6000	horizontal	B	right	1 mm	both sides	10	0,5	6000
K1301.00221013X0300	horizontal	B	right	1 mm	both sides	13	0,5	300
K1301.00221013X0500	horizontal	B	right	1 mm	both sides	13	0,5	500
K1301.00221013X1000	horizontal	B	right	1 mm	both sides	13	0,5	1000
K1301.00221013X2000	horizontal	B	right	1 mm	both sides	13	0,5	2000
K1301.00221013X3000	horizontal	B	right	1 mm	both sides	13	0,5	3000
K1301.00221013X5000	horizontal	B	right	1 mm	both sides	13	0,5	5000
K1301.00221013X6000	horizontal	B	right	1 mm	both sides	13	0,5	6000
K1301.00121013X0800	horizontal	C	centre	1 mm	both sides	13	0,5	800
K1301.00121013X2000	horizontal	C	centre	1 mm	both sides	13	0,5	2000
K1301.00121013X2500	horizontal	C	centre	1 mm	both sides	13	0,5	2500
K1301.00121013X8000	horizontal	C	centre	1 mm	both sides	13	0,5	8000
K1301.01021013X1000	vertical	D	top	1 mm	both sides	13	0,5	1000
K1301.01021013X2000	vertical	D	top	1 mm	both sides	13	0,5	2000
K1301.01021013X3000	vertical	D	top	1 mm	both sides	13	0,5	3000
K1301.01021013X5000	vertical	D	top	1 mm	both sides	13	0,5	5000
K1301.01221013X1000	vertical	E	bottom	1 mm	both sides	13	0,5	1000
K1301.01221013X2000	vertical	E	bottom	1 mm	both sides	13	0,5	2000
K1301.01221013X3000	vertical	E	bottom	1 mm	both sides	13	0,5	3000
K1301.01221013X5000	vertical	E	bottom	1 mm	both sides	13	0,5	5000