


# Clamping element "actima"

## Item description/product images

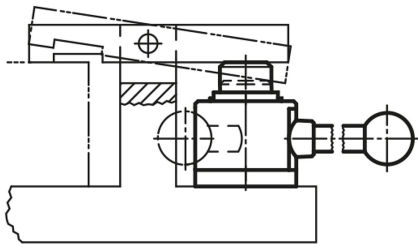

## Description

### Material:

Steel.

Housing thermoplastic.

Ball knob thermoset PF 31.

Accessories steel.

### Version:

Black oxidised.

Housing black.

Ball knob, red.


Accessories black oxidised.

### Note:


The travel path is 10 mm. Self-locking occurs in any position within only 2 mm of clamp travel, so workpieces with tolerances of up to 1.5 mm can be safely clamped. The Actima clamping device can be mounted in any horizontal or vertical position. Standard parts enable further applications and are available as optional accessories. All parts of the cam system subject to heavy loads are case-hardened (thrust sleeve and accessories only if specified). The maximum permissible clamping force is approximately 4905 N.

## Drawings





View from below

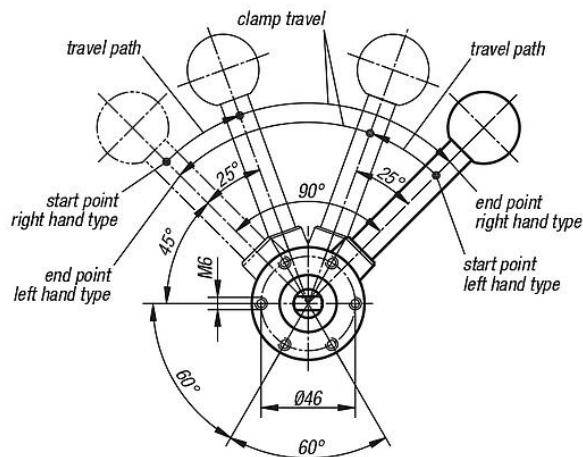

drilled through

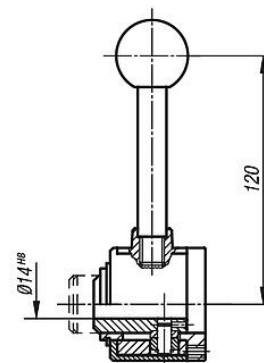


with transverse axis in bore

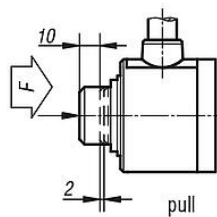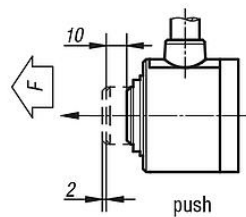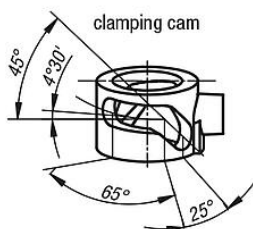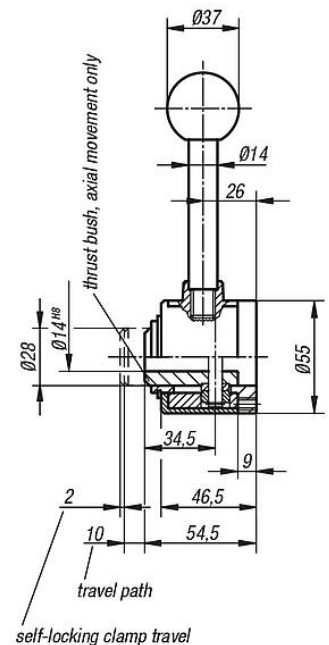


# Clamping element "actima"


## Drawings

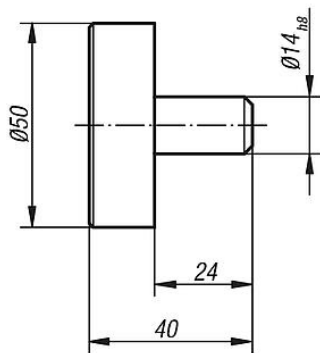

plate

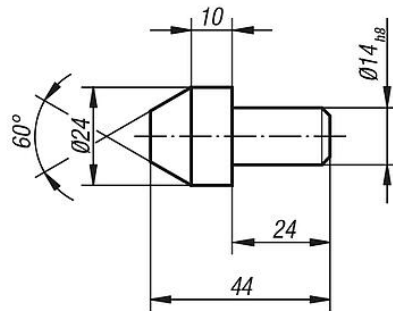

conus

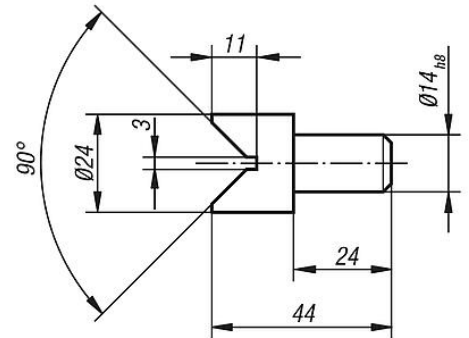

prism

## Overview of items

### "actima" accessories

| Order No. | Item  |
|-----------|-------|
| K0020.02  | Plate |
| K0020.03  | Conus |
| K0020.04  | Prism |