

Hook wrench with pin DIN 1810B

Item description/product images




Description

Material:
Special steel.

Version:
Hardened and annealed in black oxide tone.

Note:
For DIN 1816 round nut with set pin holes.
With rounded edges for better handling.

Drawings

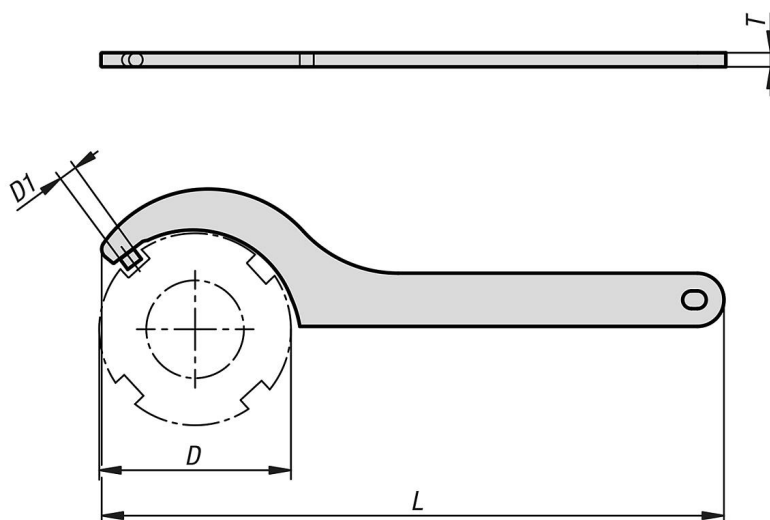

Overview of items

Hook wrench with pin DIN 1810B

Order No.		D min.	D max.	D1	L	T
K2401.012014	-	12	14	2	110	3
K2401.020022	-	20	22	2,5	110	3
K2401.016018	-	16	18	2,5	110	3
K2401.025028	M10, M12	25	28	3	136	4
K2401.030032	M14, M16	30	32	4	136	4
K2401.034036	M18, M20	34	36	4	170	5
K2401.040042	M22, M24	40	42	4	170	5
K2401.052055	M32, M35	52	55	5	206	6
K2401.045050	M26 - M30	45	50	5	206	6
K2401.058062	M38 - M42	58	62	5	240	7
K2401.068075	M45 - M50	68	75	6	240	7
K2401.095100	M62 - M70	95	100	8	280	8
K2401.080090	M52 - M60	80	90	6	280	8

Hook wrench with pin DIN 1810B

Overview of items
