


Hexagon nuts thin DIN 439 / ISO 4035

Item description/product images

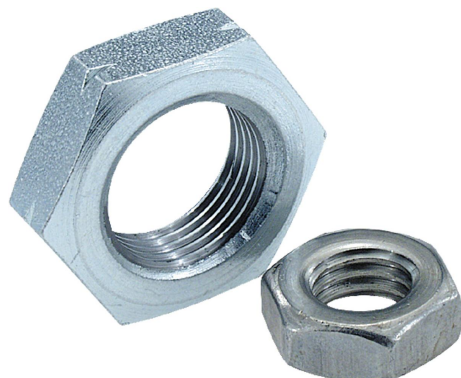

Description

Material:

Steel, stainless steel A2 or stainless steel A4.

Version:

Steel grade 04, electro zinc-plated or black oxidised.

Stainless steel A2, bright.


Stainless steel A4, bright.

Note:

These hexagon nuts are used in screw connections exposed to limited loads, e.g. as a locknut for clevis joints or rod ends.

The maximum nut height H max. is shown in the table.

Drawings

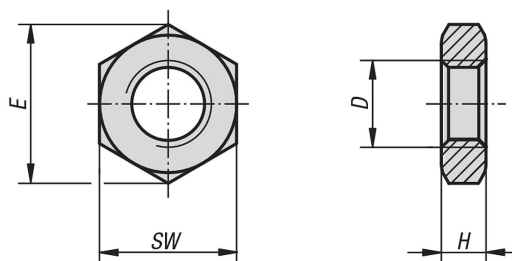

Overview of items

Hexagon nuts thin DIN 439 / ISO 4035

Order No.	Main material	Surface finish body	Version 2	D	E	H	SW	DIN	ISO
K0700.006	steel	galvanised	RH thread	M6X0,75	11,05	3,2	10	DIN 439	-
K0700.008	steel	galvanised	RH thread	M8X1	14,38	4	13	DIN 439	-
K0700.05	steel	galvanised	RH thread	M5	8,79	2,7	8	DIN 439	-
K0700.06	steel	galvanised	RH thread	M6	11,05	3,2	10	DIN 439	-
K0700.061	steel	galvanised	LH thread	M6	11,05	3,2	10	DIN 439	-
K0700.08	steel	galvanised	RH thread	M8	14,38	4	13	DIN 439	-
K0700.081	steel	galvanised	LH thread	M8	14,38	4	13	DIN 439	-
K0700.10	steel	galvanised	RH thread	M10	18,9	5	17	DIN 439	-
K0700.101	steel	galvanised	LH thread	M10	18,9	5	17	DIN 439	-
K0700.103	steel	galvanised	RH thread	M10X1	18,9	5	17	DIN 439	-
K0700.1031	steel	galvanised	LH thread	M10X1	18,9	5	17	DIN 439	-
K0700.104	steel	galvanised	RH thread	M10X1,25	18,9	5	17	DIN 439	-
K0700.1041	steel	galvanised	LH thread	M10X1,25	18,9	5	17	DIN 439	-
K0700.12	steel	galvanised	RH thread	M12	21,1	6	19	DIN 439	-
K0700.121	steel	galvanised	LH thread	M12	21,1	6	19	DIN 439	-
K0700.123	steel	galvanised	RH thread	M12X1,25	21,1	6	19	DIN 439	-
K0700.1231	steel	galvanised	LH thread	M12X1,25	21,1	6	19	DIN 439	-
K0700.124	steel	galvanised	RH thread	M12X1,5	21,1	6	19	DIN 439	-
K0700.1241	steel	galvanised	LH thread	M12X1,5	21,1	6	19	DIN 439	-
K0700.16	steel	galvanised	RH thread	M16	26,76	8	24	DIN 439	-
K0700.161	steel	galvanised	LH thread	M16	26,76	8	24	DIN 439	-
K0700.163	steel	galvanised	RH thread	M16x1,5	26,76	8	24	DIN 439	-
K0700.183	steel	galvanised	RH thread	M18x1,5	29,56	9	27	DIN 439	-
K0700.203	steel	galvanised	RH thread	M20X1,5	32,95	10	30	DIN 439	-
K0700.2031	steel	galvanised	LH thread	M20X1,5	32,95	10	30	DIN 439	-

Hexagon nuts thin DIN 439 / ISO 4035

Overview of items

Order No.	Main material	Surface finish body	Version 2	D	E	H	SW	DIN	ISO
K0700.223	steel	galvanised	RH thread	M22x1,5	36,9	10	32	DIN 439	-
K0700.2231	steel	galvanised	LH thread	M22x1,5	36,9	10	32	DIN 439	-
K0700.14	steel	galvanised	RH thread	M14	24,49	7	22	DIN 439	-
K0700.20	steel	galvanised	RH thread	M20	32,95	10	30	DIN 439	-
K0700.24	steel	galvanised	RH thread	M24	39,55	12	36	DIN 439	-
K0700.30	steel	galvanised	RH thread	M30	50,85	15	46	DIN 439	-
K0700.205	steel	black oxidised	RH thread	M5	8,79	2,7	8	DIN 439	-
K0700.206	steel	black oxidised	RH thread	M6	11,05	3,2	10	DIN 439	-
K0700.2063	steel	black oxidised	RH thread	M6X0,75	11,05	3,2	10	DIN 439	-
K0700.208	steel	black oxidised	RH thread	M8	14,38	4	13	DIN 439	-
K0700.2083	steel	black oxidised	RH thread	M8X1	14,38	4	13	DIN 439	-
K0700.210	steel	black oxidised	RH thread	M10	18,9	5	17	DIN 439	-
K0700.2103	steel	black oxidised	RH thread	M10X1	18,9	5	17	DIN 439	-
K0700.212	steel	black oxidised	RH thread	M12	21,1	6	19	DIN 439	-
K0700.2124	steel	black oxidised	RH thread	M12X1,5	21,1	6	19	DIN 439	-
K0700.216	steel	black oxidised	RH thread	M16	26,76	8	24	DIN 439	-
K0700.2163	steel	black oxidised	RH thread	M16x1,5	26,76	8	24	DIN 439	-
K0700.2203	steel	black oxidised	RH thread	M20X1,5	32,95	10	30	DIN 439	-
K0700.2243	steel	black oxidised	RH thread	M24x2	39,6	12	36	DIN 439	-
K0700.105	stainless steel A2	bright	RH thread	M5	8,79	2,7	8	DIN 439	-
K0700.106	stainless steel A2	bright	RH thread	M6	11,05	3,2	10	DIN 439	-
K0700.1061	stainless steel A2	bright	LH thread	M6	11,05	3,2	10	DIN 439	-
K0700.1062	stainless steel A2	bright	RH thread	M6X0,75	11,05	3,2	10	DIN 439	-
K0700.108	stainless steel A2	bright	RH thread	M8	14,38	4	13	DIN 439	-
K0700.1081	stainless steel A2	bright	LH thread	M8	14,38	4	13	DIN 439	-
K0700.1083	stainless steel A2	bright	RH thread	M8X1	14,38	4	13	DIN 439	-
K0700.110	stainless steel A2	bright	RH thread	M10	18,9	5	17	DIN 439	-
K0700.1101	stainless steel A2	bright	LH thread	M10	18,9	5	17	DIN 439	-
K0700.1103	stainless steel A2	bright	RH thread	M10X1	18,9	5	17	DIN 439	-
K0700.11031	stainless steel A2	bright	LH thread	M10X1	18,9	5	17	DIN 439	-
K0700.1104	stainless steel A2	bright	RH thread	M10X1,25	18,9	5	17	DIN 439	-
K0700.11041	stainless steel A2	bright	LH thread	M10X1,25	18,9	5	17	DIN 439	-
K0700.112	stainless steel A2	bright	RH thread	M12	21,1	6	19	DIN 439	-
K0700.1121	stainless steel A2	bright	LH thread	M12	21,1	6	19	DIN 439	-
K0700.1123	stainless steel A2	bright	RH thread	M12X1,25	21,1	6	19	DIN 439	-
K0700.11231	stainless steel A2	bright	LH thread	M12X1,25	21,1	6	19	DIN 439	-
K0700.1124	stainless steel A2	bright	RH thread	M12X1,5	21,1	6	19	DIN 439	-
K0700.116	stainless steel A2	bright	RH thread	M16	26,76	8	24	DIN 439	-
K0700.1161	stainless steel A2	bright	LH thread	M16	26,76	8	24	DIN 439	-
K0700.1163	stainless steel A2	bright	RH thread	M16x1,5	26,76	8	24	DIN 439	-
K0700.120	stainless steel A2	bright	RH thread	M20	32,95	10	30	DIN 439	-
K0700.1203	stainless steel A2	bright	RH thread	M20X1,5	32,95	10	30	DIN 439	-
K0700.12031	stainless steel A2	bright	LH thread	M20X1,5	32,95	10	30	DIN 439	-
K0700.1223	stainless steel A2	bright	RH thread	M22x1,5	36,9	10	32	DIN 439	-
K0700.12231	stainless steel A2	bright	LH thread	M22x1,5	36,9	10	32	DIN 439	-
K0700.1243	stainless steel A2	bright	RH thread	M24x2	39,6	12	36	DIN 439	-
K0700.114	stainless steel A2	bright	RH thread	M14	24,49	7	22	DIN 439	-
K0700.1244	stainless steel A2	bright	RH thread	M24	39,55	12	36	DIN 439	-
K0700.605	stainless steel A4	bright	RH thread	M5	8,79	2,7	8	DIN 439	-
K0700.606	stainless steel A4	bright	RH thread	M6	11,05	3,2	10	DIN 439	-
K0700.6062	stainless steel A4	bright	RH thread	M6X0,75	11,05	3,2	10	DIN 439	-
K0700.608	stainless steel A4	bright	RH thread	M8	14,38	4	13	DIN 439	-
K0700.6083	stainless steel A4	bright	RH thread	M8X1	14,38	4	13	DIN 439	-
K0700.610	stainless steel A4	bright	RH thread	M10	18,9	5	17	DIN 439	-
K0700.6103	stainless steel A4	bright	RH thread	M10X1	18,9	5	17	DIN 439	-
K0700.6104	stainless steel A4	bright	RH thread	M10X1,25	18,9	5	17	DIN 439	-
K0700.612	stainless steel A4	bright	RH thread	M12	21,1	6	19	DIN 439	-
K0700.6123	stainless steel A4	bright	RH thread	M12X1,25	21,1	6	19	DIN 439	-
K0700.6124	stainless steel A4	bright	RH thread	M12X1,5	21,1	6	19	DIN 439	-
K0700.614	stainless steel A4	bright	RH thread	M14	24,49	7	22	DIN 439	-
K0700.616	stainless steel A4	bright	RH thread	M16	26,76	8	24	DIN 439	-
K0700.6163	stainless steel A4	bright	RH thread	M16x1,5	26,76	8	24	DIN 439	-

Hexagon nuts thin DIN 439 / ISO 4035

Overview of items

Order No.	Main material	Surface finish body	Version 2	D	E	H	SW	DIN	ISO
K0700.620	stainless steel A4	bright	RH thread	M20	32,95	10	30	DIN 439	-
K0700.6203	stainless steel A4	bright	RH thread	M20x1,5	32,95	10	30	DIN 439	-
K0700.6223	stainless steel A4	bright	RH thread	M22x1,5	36,9	10	32	DIN 439	-
K0700.6244	stainless steel A4	bright	RH thread	M24	39,55	12	36	DIN 439	-
K0700.6243	stainless steel A4	bright	RH thread	M24x2	39,6	12	36	DIN 439	-