

Knurled knobs with grip, Form H, without cross hole


Item description/product images




Description

Material:
Black thermoplastic.
Bush grade 5.8 steel.

Version:
Steel trivalent blue-passivated.

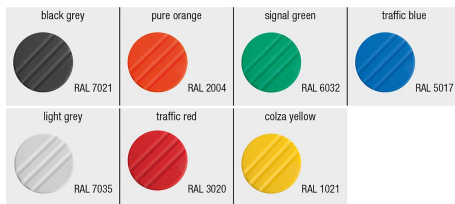

Drawings

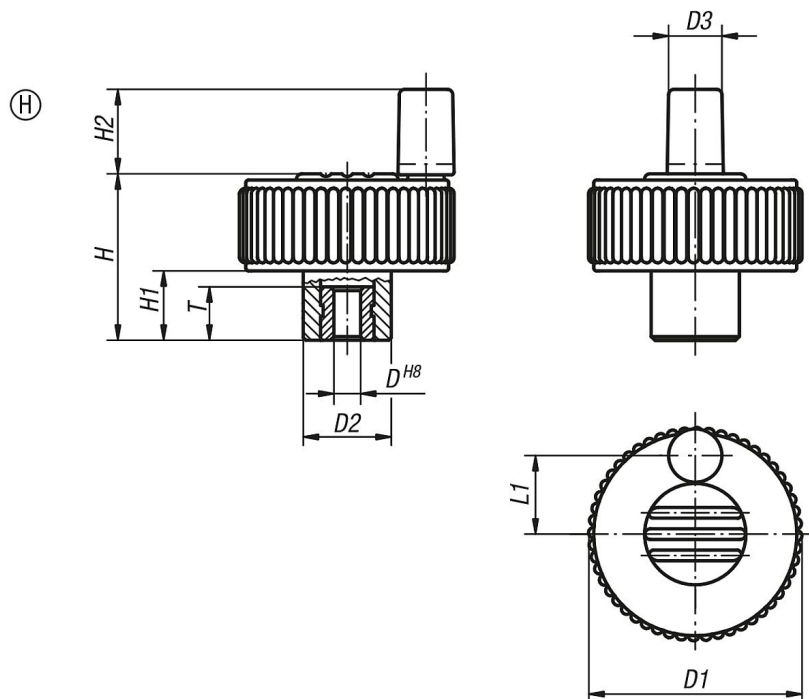

Overview of items

Knurled knobs with grip

Order No.	Form	Colour Cap	D	D1	D2	D3	H	H1	H2	L1	T
K0262.2106	H	black grey RAL 7021	6H8	40	16,5	10	31	13	16	15	10
K0262.21061	H	orange RAL 2004	6H8	40	16,5	10	31	13	16	15	10
K0262.21062	H	signal green RAL6032	6H8	40	16,5	10	31	13	16	15	10
K0262.21063	H	blue RAL5017	6H8	40	16,5	10	31	13	16	15	10
K0262.21065	H	light grey RAL 7035	6H8	40	16,5	10	31	13	16	15	10
K0262.21066	H	traffic red RAL 3020	6H8	40	16,5	10	31	13	16	15	10

Knurled knobs with grip, Form H, without cross hole

Overview of items

Order No.	Form	Colour Cap	D	D1	D2	D3	H	H1	H2	L1	T
K0262.21067	H	colza yellow RAL 1021	6H8	40	16,5	10	31	13	16	15	10
K0262.2206	H	black grey RAL 7021	6H8	50	18	10	36	15	16	18,5	10
K0262.22061	H	orange RAL 2004	6H8	50	18	10	36	15	16	18,5	10
K0262.22062	H	signal green RAL6032	6H8	50	18	10	36	15	16	18,5	10
K0262.22063	H	blue RAL5017	6H8	50	18	10	36	15	16	18,5	10
K0262.22065	H	light grey RAL 7035	6H8	50	18	10	36	15	16	18,5	10
K0262.22066	H	traffic red RAL 3020	6H8	50	18	10	36	15	16	18,5	10
K0262.22067	H	colza yellow RAL 1021	6H8	50	18	10	36	15	16	18,5	10
K0262.2308	H	black grey RAL 7021	8H8	63	22	10	41	17	16	25	14
K0262.23081	H	orange RAL 2004	8H8	63	22	10	41	17	16	25	14
K0262.23082	H	signal green RAL6032	8H8	63	22	10	41	17	16	25	14
K0262.23083	H	blue RAL5017	8H8	63	22	10	41	17	16	25	14
K0262.23085	H	light grey RAL 7035	8H8	63	22	10	41	17	16	25	14
K0262.23086	H	traffic red RAL 3020	8H8	63	22	10	41	17	16	25	14
K0262.23087	H	colza yellow RAL 1021	8H8	63	22	10	41	17	16	25	14