

Star grips

Item description/product images



Description

Material:

Fibreglass reinforced thermoplastic.
Tapped bush brass.
Screw steel.


Version:

Grip, black.
Screw electro zinc-plated.

Drawing reference:

Form D: tapped bush, without cap
Form K: tapped bush
Form L: external thread

Drawings

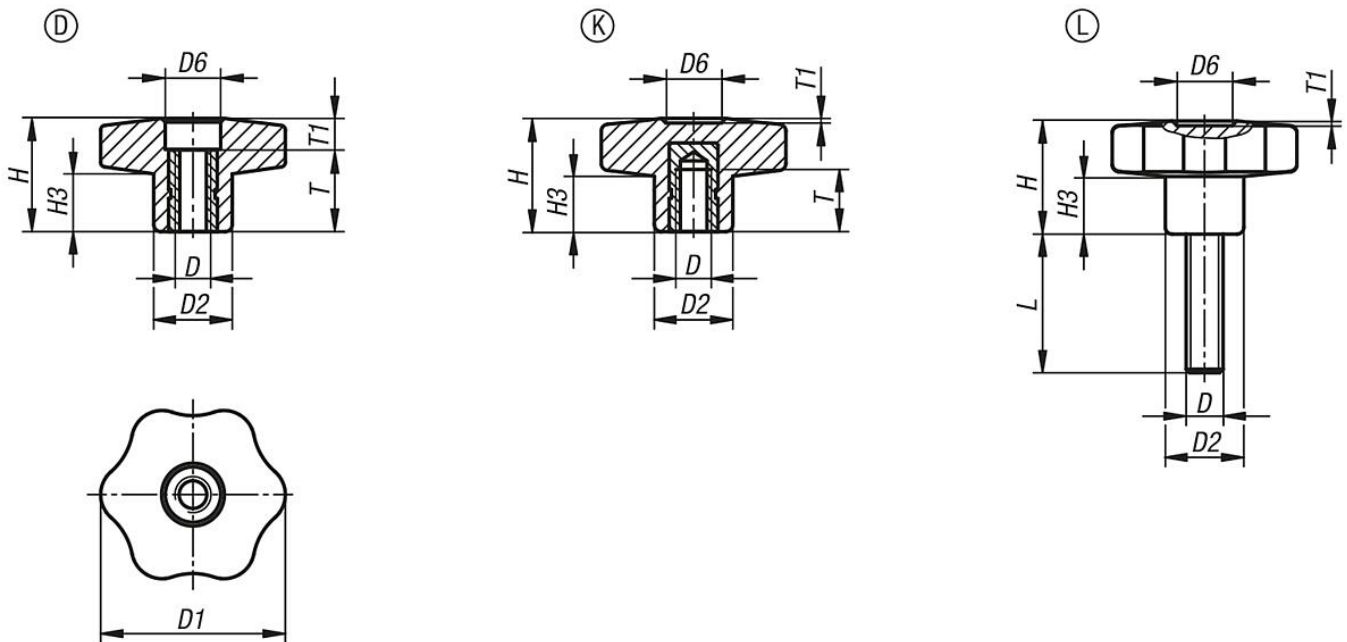

Overview of items

| Order No. | Form | D | D1 | D2 | D6 | H | H3 | L | T | T1 |
|-------------|------|-----|----|----|------|------|------|---|----|-----|
| K1090.53005 | D | M5 | 30 | 15 | 11 | 22 | 11 | - | 18 | 4 |
| K1090.53006 | D | M6 | 30 | 15 | 11 | 22 | 11 | - | 18 | 4 |
| K1090.53008 | D | M8 | 30 | 15 | 11 | 22 | 11 | - | 18 | 4 |
| K1090.54006 | D | M6 | 40 | 17 | 12,5 | 24,5 | 12,5 | - | 18 | 6 |
| K1090.54008 | D | M8 | 40 | 17 | 12,5 | 24,5 | 12,5 | - | 18 | 6 |
| K1090.54010 | D | M10 | 40 | 17 | 12,5 | 24,5 | 12,5 | - | 18 | 6 |
| K1090.55008 | D | M8 | 50 | 20 | 14 | 29 | 15,5 | - | 18 | 11 |
| K1090.55010 | D | M10 | 50 | 20 | 14 | 29 | 15,5 | - | 18 | 11 |
| K1090.55012 | D | M12 | 50 | 20 | 14 | 29 | 14 | - | 18 | 11 |
| K1090.56010 | D | M10 | 60 | 24 | 16,5 | 34 | 18 | - | 18 | 16 |
| K1090.56012 | D | M12 | 60 | 24 | 16,5 | 34 | 18 | - | 18 | 16 |
| K1090.23005 | K | M5 | 30 | 15 | 9 | 22 | 11 | - | 14 | 1,5 |
| K1090.23006 | K | M6 | 30 | 15 | 9 | 22 | 11 | - | 10 | 1,5 |
| K1090.24006 | K | M6 | 40 | 17 | 12 | 24,5 | 12 | - | 16 | 1 |

Overview of items

| Order No. | Form | D | D1 | D2 | D6 | H | H3 | L | T | T1 |
|--------------|------|-----|----|----|------|------|------|-------------|----|-----|
| K1090.24008 | K | M8 | 40 | 17 | 12 | 24,5 | 12 | - | 14 | 1 |
| K1090.24010 | K | M10 | 40 | 17 | 12 | 24,5 | 12 | - | 14 | 1 |
| K1090.25008 | K | M8 | 50 | 20 | 14,5 | 29 | 15,5 | - | 14 | 1,5 |
| K1090.25010 | K | M10 | 50 | 20 | 14,5 | 29 | 15,5 | - | 14 | 1,5 |
| K1090.25012 | K | M12 | 50 | 20 | 14,5 | 29 | 15,5 | - | 18 | 1,5 |
| K1090.26010 | K | M10 | 60 | 24 | 18 | 34 | 18 | - | 21 | 1,5 |
| K1090.26012 | K | M12 | 60 | 24 | 18 | 34 | 18 | - | 18 | 1,5 |
| K1090.43006X | L | M6 | 30 | 15 | 9 | 22 | 11 | 16/20/30 | - | 1,5 |
| K1090.43008X | L | M8 | 30 | 15 | 9 | 22 | 11 | 16/20/30/40 | - | 1,5 |
| K1090.44006X | L | M6 | 40 | 17 | 12 | 24,5 | 12,5 | 16/20/30/40 | - | 1 |
| K1090.44008X | L | M8 | 40 | 17 | 12 | 24,5 | 12,5 | 20/30/40/50 | - | 1 |
| K1090.45008X | L | M8 | 50 | 20 | 14,5 | 29 | 15 | 20/30/40 | - | 1,5 |
| K1090.45010X | L | M10 | 50 | 20 | 14,5 | 29 | 15 | 20/30/40/50 | - | 1,5 |
| K1090.46010X | L | M10 | 60 | 24 | 18 | 34 | 18 | 20/30/40/50 | - | 1,5 |
| K1090.46012X | L | M12 | 60 | 24 | 18 | 34 | 18 | 20/30/40/50 | - | 1,5 |