

## Parallel keys DIN 6885 A

### Item description/product images



### Description


**Material:**

Steel 1.1192 or stainless steel 1.4571.


**Version:**

Bright.

### Application example:

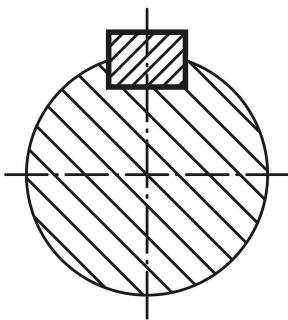

### Drawings

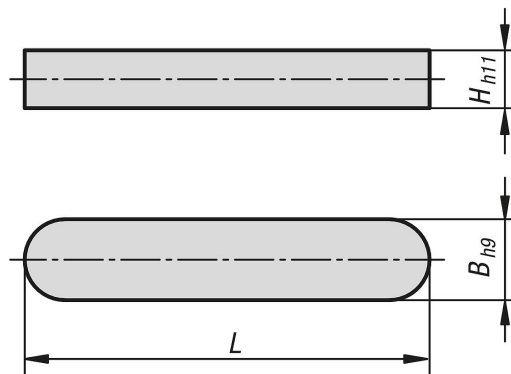

### Overview of items

#### Parallel keys DIN 6885 A

Order No.	Main material	B	H	L = length
K0696.03X8	steel	3	3	8
K0696.03X10	steel	3	3	10
K0696.03X12	steel	3	3	12
K0696.03X14	steel	3	3	14
K0696.03X16	steel	3	3	16
K0696.03X18	steel	3	3	18
K0696.03X20	steel	3	3	20
K0696.03X22	steel	3	3	22
K0696.03X25	steel	3	3	25

## Parallel keys DIN 6885 A

### Overview of items

Order No.	Main material	B	H	L = length
K0696.03X28	steel	3	3	28
K0696.04X8	steel	4	4	8
K0696.04X10	steel	4	4	10
K0696.04X12	steel	4	4	12
K0696.04X14	steel	4	4	14
K0696.04X16	steel	4	4	16
K0696.04X18	steel	4	4	18
K0696.04X20	steel	4	4	20
K0696.04X22	steel	4	4	22
K0696.04X25	steel	4	4	25
K0696.04X28	steel	4	4	28
K0696.05X12	steel	5	5	12
K0696.05X14	steel	5	5	14
K0696.05X16	steel	5	5	16
K0696.05X18	steel	5	5	18
K0696.05X20	steel	5	5	20
K0696.05X22	steel	5	5	22
K0696.05X25	steel	5	5	25
K0696.05X28	steel	5	5	28
K0696.05X32	steel	5	5	32
K0696.05X36	steel	5	5	36
K0696.05X40	steel	5	5	40
K0696.06X12	steel	6	6	12
K0696.06X14	steel	6	6	14
K0696.06X16	steel	6	6	16
K0696.06X18	steel	6	6	18
K0696.06X20	steel	6	6	20
K0696.06X22	steel	6	6	22
K0696.06X25	steel	6	6	25
K0696.06X28	steel	6	6	28
K0696.06X32	steel	6	6	32
K0696.06X36	steel	6	6	36
K0696.06X40	steel	6	6	40
K0696.06X45	steel	6	6	45
K0696.08X14	steel	8	7	14
K0696.08X16	steel	8	7	16
K0696.08X18	steel	8	7	18
K0696.08X20	steel	8	7	20
K0696.08X22	steel	8	7	22
K0696.08X25	steel	8	7	25
K0696.08X28	steel	8	7	28
K0696.08X32	steel	8	7	32
K0696.08X36	steel	8	7	36
K0696.08X40	steel	8	7	40
K0696.08X45	steel	8	7	45
K0696.08X50	steel	8	7	50
K0696.08X70	steel	8	7	70
K0696.10X22	steel	10	8	22
K0696.10X25	steel	10	8	25
K0696.10X28	steel	10	8	28
K0696.10X32	steel	10	8	32
K0696.10X36	steel	10	8	36
K0696.10X40	steel	10	8	40
K0696.10X45	steel	10	8	45
K0696.10X50	steel	10	8	50
K0696.10X56	steel	10	8	56
K0696.10X70	steel	10	8	70
K0696.10X80	steel	10	8	80
K0696.12X25	steel	12	8	25
K0696.12X28	steel	12	8	28
K0696.12X32	steel	12	8	32
K0696.12X36	steel	12	8	36

## Parallel keys DIN 6885 A

### Overview of items

Order No.	Main material	B	H	L = length
K0696.12X40	steel	12	8	40
K0696.12X45	steel	12	8	45
K0696.12X50	steel	12	8	50
K0696.12X56	steel	12	8	56
K0696.12X70	steel	12	8	70
K0696.12X80	steel	12	8	80
K0696.14X25	steel	14	9	25
K0696.14X28	steel	14	9	28
K0696.14X32	steel	14	9	32
K0696.14X36	steel	14	9	36
K0696.14X40	steel	14	9	40
K0696.14X45	steel	14	9	45
K0696.14X50	steel	14	9	50
K0696.14X56	steel	14	9	56
K0696.14X70	steel	14	9	70
K0696.14X80	steel	14	9	80
K0696.16X50	steel	16	10	50
K0696.16X56	steel	16	10	56
K0696.16X63	steel	16	10	63
K0696.16X70	steel	16	10	70
K0696.16X80	steel	16	10	80
K0696.16X90	steel	16	10	90
K0696.16X100	steel	16	10	100
K0696.103X10	stainless steel	3	3	10
K0696.103X12	stainless steel	3	3	12
K0696.103X16	stainless steel	3	3	16
K0696.103X20	stainless steel	3	3	20
K0696.104X10	stainless steel	4	4	10
K0696.104X12	stainless steel	4	4	12
K0696.104X14	stainless steel	4	4	14
K0696.104X16	stainless steel	4	4	16
K0696.104X18	stainless steel	4	4	18
K0696.104X20	stainless steel	4	4	20
K0696.104X22	stainless steel	4	4	22
K0696.105X12	stainless steel	5	5	12
K0696.105X14	stainless steel	5	5	14
K0696.105X16	stainless steel	5	5	16
K0696.105X18	stainless steel	5	5	18
K0696.105X20	stainless steel	5	5	20
K0696.105X22	stainless steel	5	5	22
K0696.105X25	stainless steel	5	5	25
K0696.105X28	stainless steel	5	5	28
K0696.105X36	stainless steel	5	5	36
K0696.105X40	stainless steel	5	5	40
K0696.106X12	stainless steel	6	6	12
K0696.106X14	stainless steel	6	6	14
K0696.106X16	stainless steel	6	6	16
K0696.106X18	stainless steel	6	6	18
K0696.106X20	stainless steel	6	6	20
K0696.106X22	stainless steel	6	6	22
K0696.106X25	stainless steel	6	6	25
K0696.106X28	stainless steel	6	6	28
K0696.106X32	stainless steel	6	6	32
K0696.106X36	stainless steel	6	6	36
K0696.106X40	stainless steel	6	6	40
K0696.108X16	stainless steel	8	7	16
K0696.108X18	stainless steel	8	7	18
K0696.108X20	stainless steel	8	7	20
K0696.108X22	stainless steel	8	7	22
K0696.108X25	stainless steel	8	7	25
K0696.108X28	stainless steel	8	7	28
K0696.108X32	stainless steel	8	7	32

## Parallel keys DIN 6885 A

### Overview of items

Order No.	Main material	B	H	L = length
K0696.108X36	stainless steel	8	7	36
K0696.108X40	stainless steel	8	7	40
K0696.108X45	stainless steel	8	7	45
K0696.108X50	stainless steel	8	7	50
K0696.108X70	stainless steel	8	7	70
K0696.110X22	stainless steel	10	8	22
K0696.110X25	stainless steel	10	8	25
K0696.110X28	stainless steel	10	8	28
K0696.110X32	stainless steel	10	8	32
K0696.110X36	stainless steel	10	8	36
K0696.110X40	stainless steel	10	8	40
K0696.110X45	stainless steel	10	8	45
K0696.110X50	stainless steel	10	8	50
K0696.110X56	stainless steel	10	8	56
K0696.110X70	stainless steel	10	8	70
K0696.110X80	stainless steel	10	8	80
K0696.112X28	stainless steel	12	8	28
K0696.112X32	stainless steel	12	8	32
K0696.112X36	stainless steel	12	8	36
K0696.112X40	stainless steel	12	8	40
K0696.112X45	stainless steel	12	8	45
K0696.112X50	stainless steel	12	8	50
K0696.112X56	stainless steel	12	8	56
K0696.112X70	stainless steel	12	8	70
K0696.112X80	stainless steel	12	8	80
K0696.114X32	stainless steel	14	9	32
K0696.114X40	stainless steel	14	9	40
K0696.114X45	stainless steel	14	9	45
K0696.114X50	stainless steel	14	9	50
K0696.114X56	stainless steel	14	9	56
K0696.114X70	stainless steel	14	9	70
K0696.114X80	stainless steel	14	9	80
K0696.116X50	stainless steel	16	10	50
K0696.116X63	stainless steel	16	10	63
K0696.116X70	stainless steel	16	10	70
K0696.116X80	stainless steel	16	10	80
K0696.116X90	stainless steel	16	10	90
K0696.116X100	stainless steel	16	10	100