


Star grips with safety cable similar to DIN 6336

Item description/product images

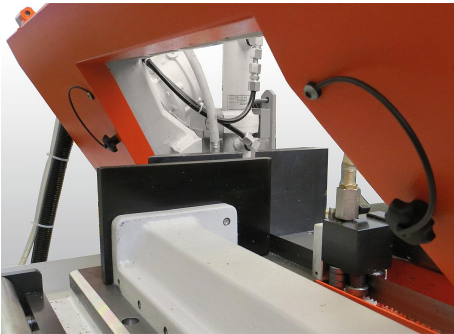

Description

Material:

Grip thermoplastic.
Bush and screw steel.
Safety cable elastic TPU.

Version:

Bush and screw trivalent blue passivated.

Note:

Δ Add the desired cap colour code here. No colour code is required for black caps.

Attach the safety cable to a base to make the star grip unlosable. The star grip cannot be moved far from the object to which it belongs, simplifying screwing and unscrewing of the grip and ensuring against loss.

Assembly:

Do not stretch the band during assembly.
Make sure that the anchor is not too far from where the star grip is to be used.



Accessory:

The safety cable is also available as an accessory, see K0743.04190.

Drawing reference:

Form KS: tapped bush, with cap
Form LS: external thread

Drawings

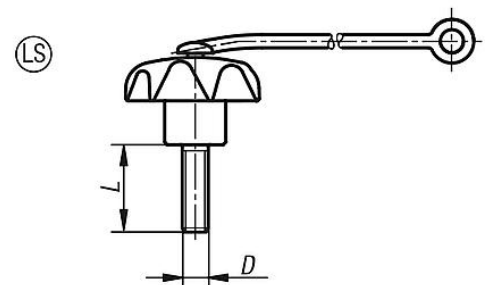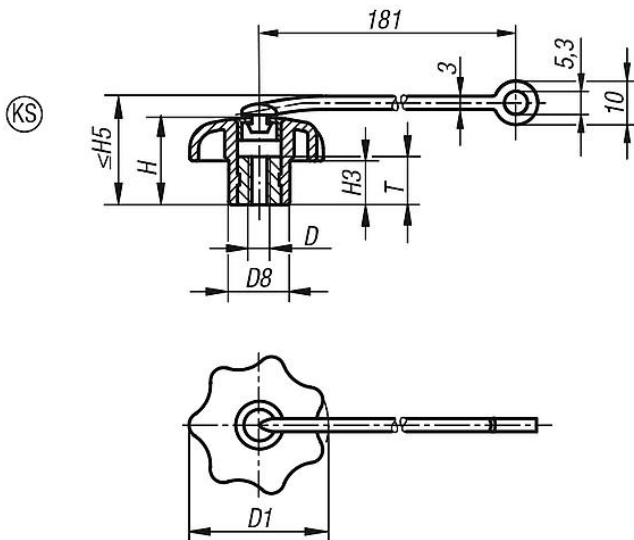

Star grips with safety cable similar to DIN 6336

Overview of items

Star grips with safety cable similar to DIN 6336

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H5 max. | T | L |
|---------------|------|-----------------------|-----|----|----|----|------------|----|----|
| K0155.604 | KS | jet black | M4 | 25 | 12 | 16 | 22 | 10 | - |
| K0155.6045 | KS | light grey RAL 7035 | M4 | 25 | 12 | 16 | 22 | 10 | - |
| K0155.6046 | KS | traffic red RAL 3020 | M4 | 25 | 12 | 16 | 22 | 10 | - |
| K0155.6047 | KS | colza yellow RAL 1021 | M4 | 25 | 12 | 16 | 22 | 10 | - |
| K0155.605 | KS | jet black | M5 | 25 | 12 | 16 | 22 | 10 | - |
| K0155.6055 | KS | light grey RAL 7035 | M5 | 25 | 12 | 16 | 22 | 10 | - |
| K0155.6056 | KS | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 22 | 10 | - |
| K0155.6057 | KS | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 22 | 10 | - |
| K0155.6061 | KS | jet black | M6 | 25 | 12 | 16 | 22 | 10 | - |
| K0155.60615 | KS | light grey RAL 7035 | M6 | 25 | 12 | 16 | 22 | 10 | - |
| K0155.60616 | KS | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 22 | 10 | - |
| K0155.60617 | KS | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 22 | 10 | - |
| K0155.6051 | KS | jet black | M5 | 32 | 14 | 20 | 26 | 10 | - |
| K0155.60515 | KS | light grey RAL 7035 | M5 | 32 | 14 | 20 | 26 | 10 | - |
| K0155.60516 | KS | traffic red RAL 3020 | M5 | 32 | 14 | 20 | 26 | 10 | - |
| K0155.60517 | KS | colza yellow RAL 1021 | M5 | 32 | 14 | 20 | 26 | 10 | - |
| K0155.606 | KS | jet black | M6 | 32 | 14 | 20 | 26 | 10 | - |
| K0155.6065 | KS | light grey RAL 7035 | M6 | 32 | 14 | 20 | 26 | 10 | - |
| K0155.6066 | KS | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 26 | 10 | - |
| K0155.6067 | KS | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 26 | 10 | - |
| K0155.608 | KS | jet black | M8 | 40 | 18 | 25 | 31 | 14 | - |
| K0155.6085 | KS | light grey RAL 7035 | M8 | 40 | 18 | 25 | 31 | 14 | - |
| K0155.6086 | KS | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 31 | 14 | - |
| K0155.6087 | KS | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 31 | 14 | - |
| K0155.6101 | KS | jet black | M10 | 40 | 18 | 25 | 31 | 14 | - |
| K0155.61015 | KS | light grey RAL 7035 | M10 | 40 | 18 | 25 | 31 | 14 | - |
| K0155.61016 | KS | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 31 | 14 | - |
| K0155.61017 | KS | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 31 | 14 | - |
| K0155.6081 | KS | jet black | M8 | 50 | 22 | 32 | 38 | 14 | - |
| K0155.60815 | KS | light grey RAL 7035 | M8 | 50 | 22 | 32 | 38 | 14 | - |
| K0155.60816 | KS | traffic red RAL 3020 | M8 | 50 | 22 | 32 | 38 | 14 | - |
| K0155.60817 | KS | colza yellow RAL 1021 | M8 | 50 | 22 | 32 | 38 | 14 | - |
| K0155.610 | KS | jet black | M10 | 50 | 22 | 32 | 38 | 14 | - |
| K0155.6105 | KS | light grey RAL 7035 | M10 | 50 | 22 | 32 | 38 | 14 | - |
| K0155.6106 | KS | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 38 | 14 | - |
| K0155.6107 | KS | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 38 | 14 | - |
| K0155.6121 | KS | jet black | M12 | 50 | 22 | 32 | 38 | 14 | - |
| K0155.61215 | KS | light grey RAL 7035 | M12 | 50 | 22 | 32 | 38 | 14 | - |
| K0155.61216 | KS | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 38 | 14 | - |
| K0155.61217 | KS | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 38 | 14 | - |
| K0155.6102 | KS | jet black | M10 | 63 | 26 | 40 | 46 | 14 | - |
| K0155.61025 | KS | light grey RAL 7035 | M10 | 63 | 26 | 40 | 46 | 14 | - |
| K0155.61026 | KS | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 46 | 14 | - |
| K0155.61027 | KS | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 46 | 14 | - |
| K0155.612 | KS | jet black | M12 | 63 | 26 | 40 | 46 | 14 | - |
| K0155.6125 | KS | light grey RAL 7035 | M12 | 63 | 26 | 40 | 46 | 14 | - |
| K0155.6126 | KS | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 46 | 14 | - |
| K0155.6127 | KS | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 46 | 14 | - |
| K0155.616 | KS | jet black | M16 | 63 | 26 | 40 | 46 | 14 | - |
| K0155.6165 | KS | light grey RAL 7035 | M16 | 63 | 26 | 40 | 46 | 14 | - |
| K0155.6166 | KS | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 46 | 14 | - |
| K0155.6167 | KS | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 46 | 14 | - |
| K0155.705X10 | LS | jet black | M5 | 25 | 12 | 16 | 22 | - | 10 |
| K0155.7055X10 | LS | light grey RAL 7035 | M5 | 25 | 12 | 16 | 22 | - | 10 |
| K0155.7056X10 | LS | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 22 | - | 10 |
| K0155.7057X10 | LS | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 22 | - | 10 |
| K0155.705X15 | LS | jet black | M5 | 25 | 12 | 16 | 22 | - | 15 |
| K0155.7055X15 | LS | light grey RAL 7035 | M5 | 25 | 12 | 16 | 22 | - | 15 |
| K0155.7056X15 | LS | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 22 | - | 15 |

Star grips with safety cable similar to DIN 6336

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H5 max. | T | L |
|---------------|------|-----------------------|----|----|----|----|------------|---|----|
| K0155.7057X15 | LS | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 22 | - | 15 |
| K0155.705X20 | LS | jet black | M5 | 25 | 12 | 16 | 22 | - | 20 |
| K0155.7055X20 | LS | light grey RAL 7035 | M5 | 25 | 12 | 16 | 22 | - | 20 |
| K0155.7056X20 | LS | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 22 | - | 20 |
| K0155.7057X20 | LS | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 22 | - | 20 |
| K0155.705X25 | LS | jet black | M5 | 25 | 12 | 16 | 22 | - | 25 |
| K0155.7055X25 | LS | light grey RAL 7035 | M5 | 25 | 12 | 16 | 22 | - | 25 |
| K0155.7056X25 | LS | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 22 | - | 25 |
| K0155.7057X25 | LS | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 22 | - | 25 |
| K0155.705X30 | LS | jet black | M5 | 25 | 12 | 16 | 22 | - | 30 |
| K0155.7055X30 | LS | light grey RAL 7035 | M5 | 25 | 12 | 16 | 22 | - | 30 |
| K0155.7056X30 | LS | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 22 | - | 30 |
| K0155.7057X30 | LS | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 22 | - | 30 |
| K0155.705X35 | LS | jet black | M5 | 25 | 12 | 16 | 22 | - | 35 |
| K0155.7055X35 | LS | light grey RAL 7035 | M5 | 25 | 12 | 16 | 22 | - | 35 |
| K0155.7056X35 | LS | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 22 | - | 35 |
| K0155.7057X35 | LS | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 22 | - | 35 |
| K0155.705X40 | LS | jet black | M5 | 25 | 12 | 16 | 22 | - | 40 |
| K0155.7055X40 | LS | light grey RAL 7035 | M5 | 25 | 12 | 16 | 22 | - | 40 |
| K0155.7056X40 | LS | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 22 | - | 40 |
| K0155.7057X40 | LS | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 22 | - | 40 |
| K0155.705X45 | LS | jet black | M5 | 25 | 12 | 16 | 22 | - | 45 |
| K0155.7055X45 | LS | light grey RAL 7035 | M5 | 25 | 12 | 16 | 22 | - | 45 |
| K0155.7056X45 | LS | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 22 | - | 45 |
| K0155.7057X45 | LS | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 22 | - | 45 |
| K0155.705X50 | LS | jet black | M5 | 25 | 12 | 16 | 22 | - | 50 |
| K0155.7055X50 | LS | light grey RAL 7035 | M5 | 25 | 12 | 16 | 22 | - | 50 |
| K0155.7056X50 | LS | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 22 | - | 50 |
| K0155.7057X50 | LS | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 22 | - | 50 |
| K0155.705X60 | LS | jet black | M5 | 25 | 12 | 16 | 22 | - | 60 |
| K0155.7055X60 | LS | light grey RAL 7035 | M5 | 25 | 12 | 16 | 22 | - | 60 |
| K0155.7056X60 | LS | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 22 | - | 60 |
| K0155.7057X60 | LS | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 22 | - | 60 |
| K0155.706X10 | LS | jet black | M6 | 25 | 12 | 16 | 22 | - | 10 |
| K0155.7065X10 | LS | light grey RAL 7035 | M6 | 25 | 12 | 16 | 22 | - | 10 |
| K0155.7066X10 | LS | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 22 | - | 10 |
| K0155.7067X10 | LS | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 22 | - | 10 |
| K0155.706X15 | LS | jet black | M6 | 25 | 12 | 16 | 22 | - | 15 |
| K0155.7065X15 | LS | light grey RAL 7035 | M6 | 25 | 12 | 16 | 22 | - | 15 |
| K0155.7066X15 | LS | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 22 | - | 15 |
| K0155.7067X15 | LS | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 22 | - | 15 |
| K0155.706X20 | LS | jet black | M6 | 25 | 12 | 16 | 22 | - | 20 |
| K0155.7065X20 | LS | light grey RAL 7035 | M6 | 25 | 12 | 16 | 22 | - | 20 |
| K0155.7066X20 | LS | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 22 | - | 20 |
| K0155.7067X20 | LS | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 22 | - | 20 |
| K0155.706X25 | LS | jet black | M6 | 25 | 12 | 16 | 22 | - | 25 |
| K0155.7065X25 | LS | light grey RAL 7035 | M6 | 25 | 12 | 16 | 22 | - | 25 |
| K0155.7066X25 | LS | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 22 | - | 25 |
| K0155.7067X25 | LS | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 22 | - | 25 |
| K0155.706X30 | LS | jet black | M6 | 25 | 12 | 16 | 22 | - | 30 |
| K0155.7065X30 | LS | light grey RAL 7035 | M6 | 25 | 12 | 16 | 22 | - | 30 |
| K0155.7066X30 | LS | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 22 | - | 30 |
| K0155.7067X30 | LS | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 22 | - | 30 |
| K0155.706X35 | LS | jet black | M6 | 25 | 12 | 16 | 22 | - | 35 |
| K0155.7065X35 | LS | light grey RAL 7035 | M6 | 25 | 12 | 16 | 22 | - | 35 |
| K0155.7066X35 | LS | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 22 | - | 35 |
| K0155.7067X35 | LS | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 22 | - | 35 |
| K0155.706X40 | LS | jet black | M6 | 25 | 12 | 16 | 22 | - | 40 |
| K0155.7065X40 | LS | light grey RAL 7035 | M6 | 25 | 12 | 16 | 22 | - | 40 |
| K0155.7066X40 | LS | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 22 | - | 40 |
| K0155.7067X40 | LS | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 22 | - | 40 |
| K0155.706X45 | LS | jet black | M6 | 25 | 12 | 16 | 22 | - | 45 |

Star grips with safety cable similar to DIN 6336

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H5 max. | T | L |
|----------------|------|-----------------------|----|----|----|----|------------|---|----|
| K0155.7065X45 | LS | light grey RAL 7035 | M6 | 25 | 12 | 16 | 22 | - | 45 |
| K0155.7066X45 | LS | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 22 | - | 45 |
| K0155.7067X45 | LS | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 22 | - | 45 |
| K0155.706X50 | LS | jet black | M6 | 25 | 12 | 16 | 22 | - | 50 |
| K0155.7065X50 | LS | light grey RAL 7035 | M6 | 25 | 12 | 16 | 22 | - | 50 |
| K0155.7066X50 | LS | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 22 | - | 50 |
| K0155.7067X50 | LS | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 22 | - | 50 |
| K0155.706X60 | LS | jet black | M6 | 25 | 12 | 16 | 22 | - | 60 |
| K0155.7065X60 | LS | light grey RAL 7035 | M6 | 25 | 12 | 16 | 22 | - | 60 |
| K0155.7066X60 | LS | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 22 | - | 60 |
| K0155.7067X60 | LS | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 22 | - | 60 |
| K0155.7061X10 | LS | jet black | M6 | 32 | 14 | 20 | 26 | - | 10 |
| K0155.70615X10 | LS | light grey RAL 7035 | M6 | 32 | 14 | 20 | 26 | - | 10 |
| K0155.70616X10 | LS | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 26 | - | 10 |
| K0155.70617X10 | LS | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 26 | - | 10 |
| K0155.7061X15 | LS | jet black | M6 | 32 | 14 | 20 | 26 | - | 15 |
| K0155.70615X15 | LS | light grey RAL 7035 | M6 | 32 | 14 | 20 | 26 | - | 15 |
| K0155.70616X15 | LS | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 26 | - | 15 |
| K0155.70617X15 | LS | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 26 | - | 15 |
| K0155.7061X20 | LS | jet black | M6 | 32 | 14 | 20 | 26 | - | 20 |
| K0155.70615X20 | LS | light grey RAL 7035 | M6 | 32 | 14 | 20 | 26 | - | 20 |
| K0155.70616X20 | LS | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 26 | - | 20 |
| K0155.70617X20 | LS | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 26 | - | 20 |
| K0155.7061X25 | LS | jet black | M6 | 32 | 14 | 20 | 26 | - | 25 |
| K0155.70615X25 | LS | light grey RAL 7035 | M6 | 32 | 14 | 20 | 26 | - | 25 |
| K0155.70616X25 | LS | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 26 | - | 25 |
| K0155.70617X25 | LS | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 26 | - | 25 |
| K0155.7061X30 | LS | jet black | M6 | 32 | 14 | 20 | 26 | - | 30 |
| K0155.70615X30 | LS | light grey RAL 7035 | M6 | 32 | 14 | 20 | 26 | - | 30 |
| K0155.70616X30 | LS | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 26 | - | 30 |
| K0155.70617X30 | LS | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 26 | - | 30 |
| K0155.7061X35 | LS | jet black | M6 | 32 | 14 | 20 | 26 | - | 35 |
| K0155.70615X35 | LS | light grey RAL 7035 | M6 | 32 | 14 | 20 | 26 | - | 35 |
| K0155.70616X35 | LS | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 26 | - | 35 |
| K0155.70617X35 | LS | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 26 | - | 35 |
| K0155.7061X40 | LS | jet black | M6 | 32 | 14 | 20 | 26 | - | 40 |
| K0155.70615X40 | LS | light grey RAL 7035 | M6 | 32 | 14 | 20 | 26 | - | 40 |
| K0155.70616X40 | LS | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 26 | - | 40 |
| K0155.70617X40 | LS | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 26 | - | 40 |
| K0155.7061X45 | LS | jet black | M6 | 32 | 14 | 20 | 26 | - | 45 |
| K0155.70615X45 | LS | light grey RAL 7035 | M6 | 32 | 14 | 20 | 26 | - | 45 |
| K0155.70616X45 | LS | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 26 | - | 45 |
| K0155.70617X45 | LS | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 26 | - | 45 |
| K0155.7061X50 | LS | jet black | M6 | 32 | 14 | 20 | 26 | - | 50 |
| K0155.70615X50 | LS | light grey RAL 7035 | M6 | 32 | 14 | 20 | 26 | - | 50 |
| K0155.70616X50 | LS | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 26 | - | 50 |
| K0155.70617X50 | LS | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 26 | - | 50 |
| K0155.7061X60 | LS | jet black | M6 | 32 | 14 | 20 | 26 | - | 60 |
| K0155.70615X60 | LS | light grey RAL 7035 | M6 | 32 | 14 | 20 | 26 | - | 60 |
| K0155.70616X60 | LS | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 26 | - | 60 |
| K0155.70617X60 | LS | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 26 | - | 60 |
| K0155.708X15 | LS | jet black | M8 | 32 | 14 | 20 | 26 | - | 15 |
| K0155.7085X15 | LS | light grey RAL 7035 | M8 | 32 | 14 | 20 | 26 | - | 15 |
| K0155.7086X15 | LS | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 26 | - | 15 |
| K0155.7087X15 | LS | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 26 | - | 15 |
| K0155.708X20 | LS | jet black | M8 | 32 | 14 | 20 | 26 | - | 20 |
| K0155.7085X20 | LS | light grey RAL 7035 | M8 | 32 | 14 | 20 | 26 | - | 20 |
| K0155.7086X20 | LS | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 26 | - | 20 |
| K0155.7087X20 | LS | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 26 | - | 20 |
| K0155.708X25 | LS | jet black | M8 | 32 | 14 | 20 | 26 | - | 25 |
| K0155.7085X25 | LS | light grey RAL 7035 | M8 | 32 | 14 | 20 | 26 | - | 25 |
| K0155.7086X25 | LS | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 26 | - | 25 |

Star grips with safety cable similar to DIN 6336

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H5 max. | T | L |
|----------------|------|-----------------------|-----|----|----|----|------------|---|----|
| K0155.7087X25 | LS | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 26 | - | 25 |
| K0155.708X30 | LS | jet black | M8 | 32 | 14 | 20 | 26 | - | 30 |
| K0155.7085X30 | LS | light grey RAL 7035 | M8 | 32 | 14 | 20 | 26 | - | 30 |
| K0155.7086X30 | LS | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 26 | - | 30 |
| K0155.7087X30 | LS | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 26 | - | 30 |
| K0155.708X35 | LS | jet black | M8 | 32 | 14 | 20 | 26 | - | 35 |
| K0155.7085X35 | LS | light grey RAL 7035 | M8 | 32 | 14 | 20 | 26 | - | 35 |
| K0155.7086X35 | LS | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 26 | - | 35 |
| K0155.7087X35 | LS | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 26 | - | 35 |
| K0155.708X40 | LS | jet black | M8 | 32 | 14 | 20 | 26 | - | 40 |
| K0155.7085X40 | LS | light grey RAL 7035 | M8 | 32 | 14 | 20 | 26 | - | 40 |
| K0155.7086X40 | LS | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 26 | - | 40 |
| K0155.7087X40 | LS | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 26 | - | 40 |
| K0155.708X45 | LS | jet black | M8 | 32 | 14 | 20 | 26 | - | 45 |
| K0155.7085X45 | LS | light grey RAL 7035 | M8 | 32 | 14 | 20 | 26 | - | 45 |
| K0155.7086X45 | LS | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 26 | - | 45 |
| K0155.7087X45 | LS | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 26 | - | 45 |
| K0155.708X50 | LS | jet black | M8 | 32 | 14 | 20 | 26 | - | 50 |
| K0155.7085X50 | LS | light grey RAL 7035 | M8 | 32 | 14 | 20 | 26 | - | 50 |
| K0155.7086X50 | LS | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 26 | - | 50 |
| K0155.7087X50 | LS | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 26 | - | 50 |
| K0155.708X60 | LS | jet black | M8 | 32 | 14 | 20 | 26 | - | 60 |
| K0155.7085X60 | LS | light grey RAL 7035 | M8 | 32 | 14 | 20 | 26 | - | 60 |
| K0155.7086X60 | LS | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 26 | - | 60 |
| K0155.7087X60 | LS | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 26 | - | 60 |
| K0155.7081X15 | LS | jet black | M8 | 40 | 18 | 25 | 31 | - | 15 |
| K0155.70815X15 | LS | light grey RAL 7035 | M8 | 40 | 18 | 25 | 31 | - | 15 |
| K0155.70816X15 | LS | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 31 | - | 15 |
| K0155.70817X15 | LS | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 31 | - | 15 |
| K0155.7081X20 | LS | jet black | M8 | 40 | 18 | 25 | 31 | - | 20 |
| K0155.70815X20 | LS | light grey RAL 7035 | M8 | 40 | 18 | 25 | 31 | - | 20 |
| K0155.70816X20 | LS | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 31 | - | 20 |
| K0155.70817X20 | LS | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 31 | - | 20 |
| K0155.7081X25 | LS | jet black | M8 | 40 | 18 | 25 | 31 | - | 25 |
| K0155.70815X25 | LS | light grey RAL 7035 | M8 | 40 | 18 | 25 | 31 | - | 25 |
| K0155.70816X25 | LS | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 31 | - | 25 |
| K0155.70817X25 | LS | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 31 | - | 25 |
| K0155.7081X30 | LS | jet black | M8 | 40 | 18 | 25 | 31 | - | 30 |
| K0155.70815X30 | LS | light grey RAL 7035 | M8 | 40 | 18 | 25 | 31 | - | 30 |
| K0155.70816X30 | LS | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 31 | - | 30 |
| K0155.70817X30 | LS | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 31 | - | 30 |
| K0155.7081X35 | LS | jet black | M8 | 40 | 18 | 25 | 31 | - | 35 |
| K0155.70815X35 | LS | light grey RAL 7035 | M8 | 40 | 18 | 25 | 31 | - | 35 |
| K0155.70816X35 | LS | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 31 | - | 35 |
| K0155.70817X35 | LS | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 31 | - | 35 |
| K0155.7081X40 | LS | jet black | M8 | 40 | 18 | 25 | 31 | - | 40 |
| K0155.70815X40 | LS | light grey RAL 7035 | M8 | 40 | 18 | 25 | 31 | - | 40 |
| K0155.70816X40 | LS | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 31 | - | 40 |
| K0155.70817X40 | LS | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 31 | - | 40 |
| K0155.7081X45 | LS | jet black | M8 | 40 | 18 | 25 | 31 | - | 45 |
| K0155.70815X45 | LS | light grey RAL 7035 | M8 | 40 | 18 | 25 | 31 | - | 45 |
| K0155.70816X45 | LS | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 31 | - | 45 |
| K0155.70817X45 | LS | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 31 | - | 45 |
| K0155.7081X50 | LS | jet black | M8 | 40 | 18 | 25 | 31 | - | 50 |
| K0155.70815X50 | LS | light grey RAL 7035 | M8 | 40 | 18 | 25 | 31 | - | 50 |
| K0155.70816X50 | LS | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 31 | - | 50 |
| K0155.70817X50 | LS | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 31 | - | 50 |
| K0155.7081X60 | LS | jet black | M8 | 40 | 18 | 25 | 31 | - | 60 |
| K0155.70815X60 | LS | light grey RAL 7035 | M8 | 40 | 18 | 25 | 31 | - | 60 |
| K0155.70816X60 | LS | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 31 | - | 60 |
| K0155.70817X60 | LS | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 31 | - | 60 |
| K0155.710X15 | LS | jet black | M10 | 40 | 18 | 25 | 31 | - | 15 |

Star grips with safety cable similar to DIN 6336

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H5 max. | T | L |
|----------------|------|-----------------------|-----|----|----|----|------------|---|----|
| K0155.7105X15 | LS | light grey RAL 7035 | M10 | 40 | 18 | 25 | 31 | - | 15 |
| K0155.7106X15 | LS | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 31 | - | 15 |
| K0155.7107X15 | LS | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 31 | - | 15 |
| K0155.710X20 | LS | jet black | M10 | 40 | 18 | 25 | 31 | - | 20 |
| K0155.7105X20 | LS | light grey RAL 7035 | M10 | 40 | 18 | 25 | 31 | - | 20 |
| K0155.7106X20 | LS | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 31 | - | 20 |
| K0155.7107X20 | LS | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 31 | - | 20 |
| K0155.710X25 | LS | jet black | M10 | 40 | 18 | 25 | 31 | - | 25 |
| K0155.7105X25 | LS | light grey RAL 7035 | M10 | 40 | 18 | 25 | 31 | - | 25 |
| K0155.7106X25 | LS | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 31 | - | 25 |
| K0155.7107X25 | LS | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 31 | - | 25 |
| K0155.710X30 | LS | jet black | M10 | 40 | 18 | 25 | 31 | - | 30 |
| K0155.7105X30 | LS | light grey RAL 7035 | M10 | 40 | 18 | 25 | 31 | - | 30 |
| K0155.7106X30 | LS | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 31 | - | 30 |
| K0155.7107X30 | LS | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 31 | - | 30 |
| K0155.710X35 | LS | jet black | M10 | 40 | 18 | 25 | 31 | - | 35 |
| K0155.7105X35 | LS | light grey RAL 7035 | M10 | 40 | 18 | 25 | 31 | - | 35 |
| K0155.7106X35 | LS | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 31 | - | 35 |
| K0155.7107X35 | LS | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 31 | - | 35 |
| K0155.710X40 | LS | jet black | M10 | 40 | 18 | 25 | 31 | - | 40 |
| K0155.7105X40 | LS | light grey RAL 7035 | M10 | 40 | 18 | 25 | 31 | - | 40 |
| K0155.7106X40 | LS | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 31 | - | 40 |
| K0155.7107X40 | LS | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 31 | - | 40 |
| K0155.710X45 | LS | jet black | M10 | 40 | 18 | 25 | 31 | - | 45 |
| K0155.7105X45 | LS | light grey RAL 7035 | M10 | 40 | 18 | 25 | 31 | - | 45 |
| K0155.7106X45 | LS | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 31 | - | 45 |
| K0155.7107X45 | LS | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 31 | - | 45 |
| K0155.710X50 | LS | jet black | M10 | 40 | 18 | 25 | 31 | - | 50 |
| K0155.7105X50 | LS | light grey RAL 7035 | M10 | 40 | 18 | 25 | 31 | - | 50 |
| K0155.7106X50 | LS | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 31 | - | 50 |
| K0155.7107X50 | LS | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 31 | - | 50 |
| K0155.710X60 | LS | jet black | M10 | 40 | 18 | 25 | 31 | - | 60 |
| K0155.7105X60 | LS | light grey RAL 7035 | M10 | 40 | 18 | 25 | 31 | - | 60 |
| K0155.7106X60 | LS | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 31 | - | 60 |
| K0155.7107X60 | LS | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 31 | - | 60 |
| K0155.7101X15 | LS | jet black | M10 | 50 | 22 | 32 | 38 | - | 15 |
| K0155.71015X15 | LS | light grey RAL 7035 | M10 | 50 | 22 | 32 | 38 | - | 15 |
| K0155.71016X15 | LS | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 38 | - | 15 |
| K0155.71017X15 | LS | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 38 | - | 15 |
| K0155.7101X20 | LS | jet black | M10 | 50 | 22 | 32 | 38 | - | 20 |
| K0155.71015X20 | LS | light grey RAL 7035 | M10 | 50 | 22 | 32 | 38 | - | 20 |
| K0155.71016X20 | LS | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 38 | - | 20 |
| K0155.71017X20 | LS | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 38 | - | 20 |
| K0155.7101X25 | LS | jet black | M10 | 50 | 22 | 32 | 38 | - | 25 |
| K0155.71015X25 | LS | light grey RAL 7035 | M10 | 50 | 22 | 32 | 38 | - | 25 |
| K0155.71016X25 | LS | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 38 | - | 25 |
| K0155.71017X25 | LS | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 38 | - | 25 |
| K0155.7101X30 | LS | jet black | M10 | 50 | 22 | 32 | 38 | - | 30 |
| K0155.71015X30 | LS | light grey RAL 7035 | M10 | 50 | 22 | 32 | 38 | - | 30 |
| K0155.71016X30 | LS | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 38 | - | 30 |
| K0155.71017X30 | LS | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 38 | - | 30 |
| K0155.7101X35 | LS | jet black | M10 | 50 | 22 | 32 | 38 | - | 35 |
| K0155.71015X35 | LS | light grey RAL 7035 | M10 | 50 | 22 | 32 | 38 | - | 35 |
| K0155.71016X35 | LS | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 38 | - | 35 |
| K0155.71017X35 | LS | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 38 | - | 35 |
| K0155.7101X40 | LS | jet black | M10 | 50 | 22 | 32 | 38 | - | 40 |
| K0155.71015X40 | LS | light grey RAL 7035 | M10 | 50 | 22 | 32 | 38 | - | 40 |
| K0155.71016X40 | LS | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 38 | - | 40 |
| K0155.71017X40 | LS | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 38 | - | 40 |
| K0155.7101X45 | LS | jet black | M10 | 50 | 22 | 32 | 38 | - | 45 |
| K0155.71015X45 | LS | light grey RAL 7035 | M10 | 50 | 22 | 32 | 38 | - | 45 |
| K0155.71016X45 | LS | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 38 | - | 45 |

Star grips with safety cable similar to DIN 6336

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H5 max. | T | L |
|----------------|------|-----------------------|-----|----|----|----|------------|---|----|
| K0155.71017X45 | LS | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 38 | - | 45 |
| K0155.7101X50 | LS | jet black | M10 | 50 | 22 | 32 | 38 | - | 50 |
| K0155.71015X50 | LS | light grey RAL 7035 | M10 | 50 | 22 | 32 | 38 | - | 50 |
| K0155.71016X50 | LS | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 38 | - | 50 |
| K0155.71017X50 | LS | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 38 | - | 50 |
| K0155.7101X60 | LS | jet black | M10 | 50 | 22 | 32 | 38 | - | 60 |
| K0155.71015X60 | LS | light grey RAL 7035 | M10 | 50 | 22 | 32 | 38 | - | 60 |
| K0155.71016X60 | LS | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 38 | - | 60 |
| K0155.71017X60 | LS | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 38 | - | 60 |
| K0155.712X15 | LS | jet black | M12 | 50 | 22 | 32 | 38 | - | 15 |
| K0155.7125X15 | LS | light grey RAL 7035 | M12 | 50 | 22 | 32 | 38 | - | 15 |
| K0155.7126X15 | LS | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 38 | - | 15 |
| K0155.7127X15 | LS | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 38 | - | 15 |
| K0155.712X20 | LS | jet black | M12 | 50 | 22 | 32 | 38 | - | 20 |
| K0155.7125X20 | LS | light grey RAL 7035 | M12 | 50 | 22 | 32 | 38 | - | 20 |
| K0155.7126X20 | LS | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 38 | - | 20 |
| K0155.7127X20 | LS | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 38 | - | 20 |
| K0155.712X25 | LS | jet black | M12 | 50 | 22 | 32 | 38 | - | 25 |
| K0155.7125X25 | LS | light grey RAL 7035 | M12 | 50 | 22 | 32 | 38 | - | 25 |
| K0155.7126X25 | LS | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 38 | - | 25 |
| K0155.7127X25 | LS | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 38 | - | 25 |
| K0155.712X30 | LS | jet black | M12 | 50 | 22 | 32 | 38 | - | 30 |
| K0155.7125X30 | LS | light grey RAL 7035 | M12 | 50 | 22 | 32 | 38 | - | 30 |
| K0155.7126X30 | LS | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 38 | - | 30 |
| K0155.7127X30 | LS | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 38 | - | 30 |
| K0155.712X35 | LS | jet black | M12 | 50 | 22 | 32 | 38 | - | 35 |
| K0155.7125X35 | LS | light grey RAL 7035 | M12 | 50 | 22 | 32 | 38 | - | 35 |
| K0155.7126X35 | LS | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 38 | - | 35 |
| K0155.7127X35 | LS | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 38 | - | 35 |
| K0155.712X40 | LS | jet black | M12 | 50 | 22 | 32 | 38 | - | 40 |
| K0155.7125X40 | LS | light grey RAL 7035 | M12 | 50 | 22 | 32 | 38 | - | 40 |
| K0155.7126X40 | LS | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 38 | - | 40 |
| K0155.7127X40 | LS | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 38 | - | 40 |
| K0155.712X45 | LS | jet black | M12 | 50 | 22 | 32 | 38 | - | 45 |
| K0155.7125X45 | LS | light grey RAL 7035 | M12 | 50 | 22 | 32 | 38 | - | 45 |
| K0155.7126X45 | LS | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 38 | - | 45 |
| K0155.7127X45 | LS | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 38 | - | 45 |
| K0155.712X50 | LS | jet black | M12 | 50 | 22 | 32 | 38 | - | 50 |
| K0155.7125X50 | LS | light grey RAL 7035 | M12 | 50 | 22 | 32 | 38 | - | 50 |
| K0155.7126X50 | LS | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 38 | - | 50 |
| K0155.7127X50 | LS | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 38 | - | 50 |
| K0155.712X60 | LS | jet black | M12 | 50 | 22 | 32 | 38 | - | 60 |
| K0155.7125X60 | LS | light grey RAL 7035 | M12 | 50 | 22 | 32 | 38 | - | 60 |
| K0155.7126X60 | LS | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 38 | - | 60 |
| K0155.7127X60 | LS | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 38 | - | 60 |
| K0155.7102X20 | LS | jet black | M10 | 63 | 26 | 40 | 46 | - | 20 |
| K0155.71025X20 | LS | light grey RAL 7035 | M10 | 63 | 26 | 40 | 46 | - | 20 |
| K0155.71026X20 | LS | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 46 | - | 20 |
| K0155.71027X20 | LS | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 46 | - | 20 |
| K0155.7102X25 | LS | jet black | M10 | 63 | 26 | 40 | 46 | - | 25 |
| K0155.71025X25 | LS | light grey RAL 7035 | M10 | 63 | 26 | 40 | 46 | - | 25 |
| K0155.71026X25 | LS | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 46 | - | 25 |
| K0155.71027X25 | LS | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 46 | - | 25 |
| K0155.7102X30 | LS | jet black | M10 | 63 | 26 | 40 | 46 | - | 30 |
| K0155.71025X30 | LS | light grey RAL 7035 | M10 | 63 | 26 | 40 | 46 | - | 30 |
| K0155.71026X30 | LS | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 46 | - | 30 |
| K0155.71027X30 | LS | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 46 | - | 30 |
| K0155.7102X35 | LS | jet black | M10 | 63 | 26 | 40 | 46 | - | 35 |
| K0155.71025X35 | LS | light grey RAL 7035 | M10 | 63 | 26 | 40 | 46 | - | 35 |
| K0155.71026X35 | LS | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 46 | - | 35 |
| K0155.71027X35 | LS | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 46 | - | 35 |
| K0155.7102X40 | LS | jet black | M10 | 63 | 26 | 40 | 46 | - | 40 |

Star grips with safety cable similar to DIN 6336

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H5 max. | T | L |
|----------------|------|-----------------------|-----|----|----|----|------------|---|----|
| K0155.71025X40 | LS | light grey RAL 7035 | M10 | 63 | 26 | 40 | 46 | - | 40 |
| K0155.71026X40 | LS | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 46 | - | 40 |
| K0155.71027X40 | LS | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 46 | - | 40 |
| K0155.7102X45 | LS | jet black | M10 | 63 | 26 | 40 | 46 | - | 45 |
| K0155.71025X45 | LS | light grey RAL 7035 | M10 | 63 | 26 | 40 | 46 | - | 45 |
| K0155.71026X45 | LS | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 46 | - | 45 |
| K0155.71027X45 | LS | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 46 | - | 45 |
| K0155.7102X50 | LS | jet black | M10 | 63 | 26 | 40 | 46 | - | 50 |
| K0155.71025X50 | LS | light grey RAL 7035 | M10 | 63 | 26 | 40 | 46 | - | 50 |
| K0155.71026X50 | LS | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 46 | - | 50 |
| K0155.71027X50 | LS | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 46 | - | 50 |
| K0155.7102X60 | LS | jet black | M10 | 63 | 26 | 40 | 46 | - | 60 |
| K0155.71025X60 | LS | light grey RAL 7035 | M10 | 63 | 26 | 40 | 46 | - | 60 |
| K0155.71026X60 | LS | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 46 | - | 60 |
| K0155.71027X60 | LS | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 46 | - | 60 |
| K0155.7121X20 | LS | jet black | M12 | 63 | 26 | 40 | 46 | - | 20 |
| K0155.71215X20 | LS | light grey RAL 7035 | M12 | 63 | 26 | 40 | 46 | - | 20 |
| K0155.71216X20 | LS | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 46 | - | 20 |
| K0155.71217X20 | LS | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 46 | - | 20 |
| K0155.7121X25 | LS | jet black | M12 | 63 | 26 | 40 | 46 | - | 25 |
| K0155.71215X25 | LS | light grey RAL 7035 | M12 | 63 | 26 | 40 | 46 | - | 25 |
| K0155.71216X25 | LS | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 46 | - | 25 |
| K0155.71217X25 | LS | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 46 | - | 25 |
| K0155.7121X30 | LS | jet black | M12 | 63 | 26 | 40 | 46 | - | 30 |
| K0155.71215X30 | LS | light grey RAL 7035 | M12 | 63 | 26 | 40 | 46 | - | 30 |
| K0155.71216X30 | LS | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 46 | - | 30 |
| K0155.71217X30 | LS | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 46 | - | 30 |
| K0155.7121X35 | LS | jet black | M12 | 63 | 26 | 40 | 46 | - | 35 |
| K0155.71215X35 | LS | light grey RAL 7035 | M12 | 63 | 26 | 40 | 46 | - | 35 |
| K0155.71216X35 | LS | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 46 | - | 35 |
| K0155.71217X35 | LS | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 46 | - | 35 |
| K0155.7121X40 | LS | jet black | M12 | 63 | 26 | 40 | 46 | - | 40 |
| K0155.71215X40 | LS | light grey RAL 7035 | M12 | 63 | 26 | 40 | 46 | - | 40 |
| K0155.71216X40 | LS | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 46 | - | 40 |
| K0155.71217X40 | LS | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 46 | - | 40 |
| K0155.7121X45 | LS | jet black | M12 | 63 | 26 | 40 | 46 | - | 45 |
| K0155.71215X45 | LS | light grey RAL 7035 | M12 | 63 | 26 | 40 | 46 | - | 45 |
| K0155.71216X45 | LS | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 46 | - | 45 |
| K0155.71217X45 | LS | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 46 | - | 45 |
| K0155.7121X50 | LS | jet black | M12 | 63 | 26 | 40 | 46 | - | 50 |
| K0155.71215X50 | LS | light grey RAL 7035 | M12 | 63 | 26 | 40 | 46 | - | 50 |
| K0155.71216X50 | LS | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 46 | - | 50 |
| K0155.71217X50 | LS | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 46 | - | 50 |
| K0155.7121X60 | LS | jet black | M12 | 63 | 26 | 40 | 46 | - | 60 |
| K0155.71215X60 | LS | light grey RAL 7035 | M12 | 63 | 26 | 40 | 46 | - | 60 |
| K0155.71216X60 | LS | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 46 | - | 60 |
| K0155.71217X60 | LS | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 46 | - | 60 |
| K0155.716X30 | LS | jet black | M16 | 63 | 26 | 40 | 46 | - | 30 |
| K0155.7165X30 | LS | light grey RAL 7035 | M16 | 63 | 26 | 40 | 46 | - | 30 |
| K0155.7166X30 | LS | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 46 | - | 30 |
| K0155.7167X30 | LS | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 46 | - | 30 |
| K0155.716X35 | LS | jet black | M16 | 63 | 26 | 40 | 46 | - | 35 |
| K0155.7165X35 | LS | light grey RAL 7035 | M16 | 63 | 26 | 40 | 46 | - | 35 |
| K0155.7166X35 | LS | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 46 | - | 35 |
| K0155.7167X35 | LS | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 46 | - | 35 |
| K0155.716X40 | LS | jet black | M16 | 63 | 26 | 40 | 46 | - | 40 |
| K0155.7165X40 | LS | light grey RAL 7035 | M16 | 63 | 26 | 40 | 46 | - | 40 |
| K0155.7166X40 | LS | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 46 | - | 40 |
| K0155.7167X40 | LS | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 46 | - | 40 |
| K0155.716X45 | LS | jet black | M16 | 63 | 26 | 40 | 46 | - | 45 |
| K0155.7165X45 | LS | light grey RAL 7035 | M16 | 63 | 26 | 40 | 46 | - | 45 |
| K0155.7166X45 | LS | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 46 | - | 45 |

Star grips with safety cable similar to DIN 6336

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H5 max. | T | L |
|---------------|------|-----------------------|-----|----|----|----|------------|---|----|
| K0155.7167X45 | LS | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 46 | - | 45 |
| K0155.716X50 | LS | jet black | M16 | 63 | 26 | 40 | 46 | - | 50 |
| K0155.7165X50 | LS | light grey RAL 7035 | M16 | 63 | 26 | 40 | 46 | - | 50 |
| K0155.7166X50 | LS | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 46 | - | 50 |
| K0155.7167X50 | LS | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 46 | - | 50 |
| K0155.716X60 | LS | jet black | M16 | 63 | 26 | 40 | 46 | - | 60 |
| K0155.7165X60 | LS | light grey RAL 7035 | M16 | 63 | 26 | 40 | 46 | - | 60 |
| K0155.7166X60 | LS | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 46 | - | 60 |
| K0155.7167X60 | LS | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 46 | - | 60 |