

Telescopic slides, steel for side mounting, full extension, load capacity up to 272 kg

Item description/product images



Description

Material:

Slides steel.
Ball cages steel.
Balls, steel.

Version:

Slides electro zinc-plated.
Ball cages, electro zinc-plated.
Balls hardened.

Note for ordering:

Sold individually.

Note:

By telescopic slides with full extension, the travel is roughly equal to the installed length, which ensures greater comfort and accessibility. Latches in open and closed positions. The telescopic slides can only be opened or closed after the release lever has been actuated. The dynamic load capacity of the telescopic slides indicates the maximum load rating of a vertically mounted slide pair when the entire extension length is used. The load capacities specified refer to the maximum value for 10,000 cycles.

Not suitable for horizontal mounting.

The head height of the fastening screws should not exceed 4,8 mm otherwise there is a risk of collision with other parts of the slide.

These telescopic slides cannot be ordered as a pair.

If double sided latching is desired, a left and a right version must be ordered.

If single sided latching is desired, a combination with K1720 is possible.

Advantages:

Latches in open and closed positions
For heavy duty use
Manual release
Light running

Accessory:

Steel telescopic slides K1720.

Note:


The maximum load rating refers to a pair of telescopic slides.

Drawing reference:

- 1) Mounting hole by K1719.03050 and K1719.03051 not provided
- 2) Mounting hole by K1719.05590 and K1719.05591 not provided
- 3) Cut-out for carriage bolt
- 4) Reference dimension only, not a mounting hole
- 5) Form B, identical demensions as the right-hand version

Telescopic slides, steel for side mounting, full extension, load capacity up to 272 kg

Drawings

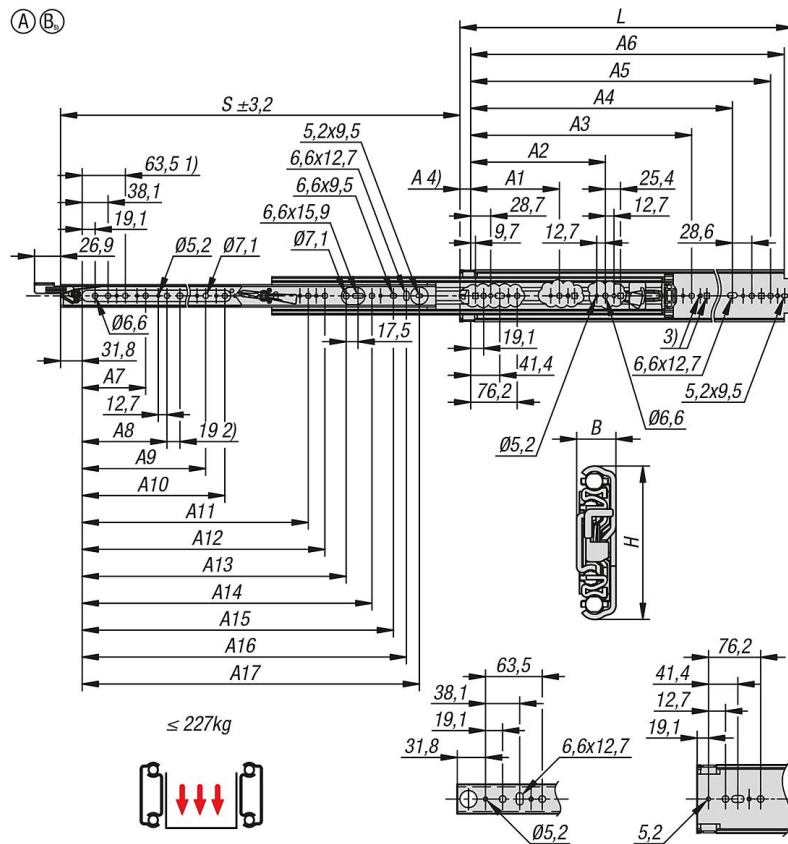

Overview of items

Steel telescopic slides for side mounting, full extension, load capacity up to 272 kg

Order No.	Form	Form definition	Assembly	Product type	Loading per pair kg	Packaging type
K1719.03050	A	left	side mounting	standard	272	packaged individually
K1719.03560	A	left	side mounting	standard	272	packaged individually
K1719.04060	A	left	side mounting	standard	272	packaged individually
K1719.04570	A	left	side mounting	standard	272	packaged individually
K1719.05080	A	left	side mounting	standard	272	packaged individually
K1719.05590	A	left	side mounting	standard	272	packaged individually
K1719.06100	A	left	side mounting	standard	267	packaged individually
K1719.06600	A	left	side mounting	standard	264	packaged individually
K1719.07110	A	left	side mounting	standard	261	packaged individually
K1719.07620	A	left	side mounting	standard	258	packaged individually
K1719.08130	A	left	side mounting	standard	256	packaged individually
K1719.08640	A	left	side mounting	standard	256	packaged individually
K1719.09140	A	left	side mounting	standard	248	packaged individually
K1719.10160	A	left	side mounting	standard	237	packaged individually
K1719.10670	A	left	side mounting	standard	228	packaged individually
K1719.12190	A	left	side mounting	standard	204	packaged individually
K1719.13720	A	left	side mounting	standard	196	packaged individually
K1719.15240	A	left	side mounting	standard	182	packaged individually
K1719.03051	B	right	side mounting	standard	272	packaged individually
K1719.03561	B	right	side mounting	standard	272	packaged individually
K1719.04061	B	right	side mounting	standard	272	packaged individually
K1719.04571	B	right	side mounting	standard	272	packaged individually
K1719.05081	B	right	side mounting	standard	272	packaged individually
K1719.05591	B	right	side mounting	standard	272	packaged individually

Telescopic slides, steel for side mounting, full extension, load capacity up to 272 kg

Overview of items

Order No.	Form	Form definition	Assembly	Product type	Loading per pair kg	Packaging type
K1719.06101	B	right	side mounting	standard	267	packaged individually
K1719.06601	B	right	side mounting	standard	264	packaged individually
K1719.07111	B	right	side mounting	standard	261	packaged individually
K1719.07621	B	right	side mounting	standard	258	packaged individually
K1719.08131	B	right	side mounting	standard	256	packaged individually
K1719.08641	B	right	side mounting	standard	256	packaged individually
K1719.09141	B	right	side mounting	standard	248	packaged individually
K1719.10161	B	right	side mounting	standard	237	packaged individually
K1719.10671	B	right	side mounting	standard	228	packaged individually
K1719.12191	B	right	side mounting	standard	204	packaged individually
K1719.13721	B	right	side mounting	standard	196	packaged individually
K1719.15241	B	right	side mounting	standard	182	packaged individually

Order No.	A	A1	A2	A3	A4	A5	A6	A7	A8	A9	A10	A11	A12	A13	A14	A15	A16	B	H	Travel S	L
K1719.03050	12,7	-	-	-	203,2	260,4	279,4	-	-	-	-	-	-	-	153,9	179,3	198,4	19,1	76,2	304,8	304,8
K1719.03560	12,7	-	-	-	254	311,2	330,2	-	-	-	-	-	-	-	204,7	230,1	249,2	19,1	76,2	355,6	355,6
K1719.04060	12,7	-	-	-	304,8	362	381	-	-	-	-	-	-	-	255,5	280,9	300	19,1	76,2	406,4	406,4
K1719.04570	12,7	-	-	-	355,6	412,8	431,8	127	-	-	-	-	-	-	306,3	331,7	350,8	19,1	76,2	457,2	457,2
K1719.05080	12,7	-	-	-	406,4	463,6	482,6	127	-	-	-	-	-	296,6	357,1	382,5	401,6	19,1	76,2	508	508
K1719.05590	12,7	-	-	-	457,2	514,4	533,4	127	190,5	-	-	-	-	347,7	407,9	433,3	452,4	19,1	76,2	558,8	558,8
K1719.06100	12,7	-	-	-	508	565,2	584,2	127	190,5	-	-	-	-	398,5	458,7	484,1	503,2	19,1	76,2	609,6	609,6
K1719.06600	12,7	-	-	-	558,8	616	635	127	190,5	-	-	-	-	449,3	509,5	534,9	554	19,1	76,2	660,4	660,4
K1719.07110	12,7	-	-	-	609,6	666,8	685,8	127	190,5	-	-	-	-	500,1	560,3	585,7	604,8	19,1	76,2	711,2	711,2
K1719.07620	12,7	235	-	501,7	660,4	717,6	736,6	127	190,5	-	-	-	-	550,9	611,1	636,5	655,6	19,1	76,2	762	762
K1719.08130	12,7	235	-	552,5	711,2	768,4	787,4	127	190,5	-	-	-	-	601,7	661,9	687,3	706,4	19,1	76,2	812,8	812,8
K1719.08640	12,7	235	-	603,2	762	819,1	838,2	127	190,5	-	520,7	-	-	652,5	712,7	738,1	757,1	19,1	76,2	863,6	863,6
K1719.09140	12,7	235	-	654,1	812,8	869,9	889	127	190,5	368,3	520,7	-	-	703,3	763,5	788,9	807,9	19,1	76,2	914,4	914,4
K1719.10160	12,7	235	-	755,7	914,4	971,5	990,6	127	190,5	368,3	-	-	-	804,9	865,1	890,5	909,5	19,1	76,2	1016	1016
K1719.10670	12,7	235	-	806,5	965,2	1022,4	1041,4	127	190,5	368,3	-	-	-	855,7	915,9	941,3	960,4	19,1	76,2	1066,8	1066,8
K1719.12190	12,7	235	-	958,9	1117,6	1174,8	1193,8	127	190,5	368,3	520,7	825,5	-	1008,1	1068,3	1093,7	1112,8	19,1	76,2	1219,2	1219,2
K1719.13720	12,7	235	-	958,9	1270	1327,2	1346,2	127	190,5	368,3	520,7	825,5	-	1160,5	1220,8	1246,2	1265,2	19,1	76,2	1371,6	1371,6
K1719.15240	12,7	235	596,6	958,9	1422,4	1479,5	1498,6	127	190,5	368,3	520,7	825,5	1130,3	1312,9	1373,1	1398,5	1417,8	19,1	76,2	1524	1524
K1719.03051	12,7	-	-	-	203,2	260,4	279,4	-	-	-	-	-	-	-	153,9	179,3	198,4	19,1	76,2	304,8	304,8
K1719.03561	12,7	-	-	-	254	311,2	330,2	-	-	-	-	-	-	-	204,7	230,1	249,2	19,1	76,2	355,6	355,6
K1719.04061	12,7	-	-	-	304,8	362	381	-	-	-	-	-	-	-	255,5	280,9	300	19,1	76,2	406,4	406,4
K1719.04571	12,7	-	-	-	355,6	412,8	431,8	127	-	-	-	-	-	-	306,3	331,7	350,8	19,1	76,2	457,2	457,2
K1719.05081	12,7	-	-	-	406,4	463,6	482,6	127	-	-	-	-	-	296,6	357,1	382,5	401,6	19,1	76,2	508	508
K1719.05591	12,7	-	-	-	457,2	514,4	533,4	127	190,5	-	-	-	-	347,7	407,9	433,3	452,4	19,1	76,2	558,8	558,8
K1719.06101	12,7	-	-	-	508	565,2	584,2	127	190,5	-	-	-	-	398,5	458,7	484,1	503,2	19,1	76,2	609,6	609,6
K1719.06601	12,7	-	-	-	558,8	616	635	127	190,5	-	-	-	-	449,3	509,5	534,9	554	19,1	76,2	660,4	660,4
K1719.07111	12,7	-	-	-	609,6	666,8	685,8	127	190,5	-	-	-	-	500,1	560,3	585,7	604,8	19,1	76,2	711,2	711,2
K1719.07621	12,7	235	-	501,7	660,4	717,6	736,6	127	190,5	-	-	-	-	550,9	611,1	636,5	655,6	19,1	76,2	762	762
K1719.08131	12,7	235	-	552,5	711,2	768,4	787,4	127	190,5	-	-	-	-	601,7	661,9	687,3	706,4	19,1	76,2	812,8	812,8
K1719.08641	12,7	235	-	603,2	762	819,1	838,2	127	190,5	-	520,7	-	-	652,5	712,7	738,1	757,1	19,1	76,2	863,6	863,6
K1719.09141	12,7	235	-	654,1	812,8	869,9	889	127	190,5	368,3	520,7	-	-	703,3	763,5	788,9	807,9	19,1	76,2	914,4	914,4
K1719.10161	12,7	235	-	755,7	914,4	971,5	990,6	127	190,5	368,3	-	-	-	804,9	865,1	890,5	909,5	19,1	76,2	1016	1016
K1719.10671	12,7	235	-	806,5	965,2	1022,4	1041,4	127	190,5	368,3	-	-	-	855,7	915,9	941,3	960,4	19,1	76,2	1066,8	1066,8
K1719.12191	12,7	235	-	958,9	1117,6	1174,8	1193,8	127	190,5	368,3	520,7	825,5	-	1008,1	1068,3	1093,7	1112,8	19,1	76,2	1219,2	1219,2
K1719.13721	12,7	235	-	958,9	1270	1327,2	1346,2	127	190,5	368,3	520,7	825,5	-	1160,5	1220,8	1246,2	1265,2	19,1	76,2	1371,6	1371,6
K1719.15241	12,7	235	596,9	958,9	1422,4	1479,5	1498,6	127	190,5	368,3	520,7	825,5	1130,3	1312,9	1373,1	1398,5	1417,8	19,1	76,2	1524	1524