

Handles, Form C

Item description/product images



Description

Material:

Knobs thermoset PF 31.


Rod steel or stainless steel 1.4305.

Version:

Thermoset black, high-gloss polished.

Steel black oxidised, blue passivated or bright stainless steel

Drawings

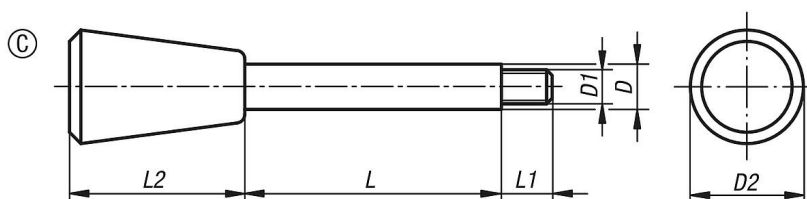

Overview of items

Order No.	Main material	Surface finish body	Form	D	D1	D2	L	L1	L2
K0179.408X35	steel	black oxidised	C	8	M6	20	35	9	31
K0179.408X50	steel	black oxidised	C	8	M6	20	50	9	31
K0179.408X65	steel	black oxidised	C	8	M6	20	65	9	31
K0179.410X50	steel	black oxidised	C	10	M8	25	50	13	38
K0179.410X65	steel	black oxidised	C	10	M8	25	65	13	38
K0179.410X80	steel	black oxidised	C	10	M8	25	80	13	38
K0179.410X100	steel	black oxidised	C	10	M8	25	100	13	38
K0179.412X65	steel	black oxidised	C	12	M10	30	65	15	46
K0179.412X80	steel	black oxidised	C	12	M10	30	80	15	46
K0179.412X100	steel	black oxidised	C	12	M10	30	100	15	46
K0179.412X125	steel	black oxidised	C	12	M10	30	125	15	46
K0179.414X80	steel	black oxidised	C	14	M12	35	80	16	53
K0179.414X100	steel	black oxidised	C	14	M12	35	100	16	53
K0179.414X125	steel	black oxidised	C	14	M12	35	125	16	53
K0179.414X160	steel	black oxidised	C	14	M12	35	160	16	53
K0179.2408X35	steel	blue-passivated	C	8	M6	20	35	9	31
K0179.2408X50	steel	blue-passivated	C	8	M6	20	50	9	31
K0179.2408X65	steel	blue-passivated	C	8	M6	20	65	9	31
K0179.2410X50	steel	blue-passivated	C	10	M8	25	50	13	38
K0179.2410X65	steel	blue-passivated	C	10	M8	25	65	13	38
K0179.2410X80	steel	blue-passivated	C	10	M8	25	80	13	38
K0179.2410X100	steel	blue-passivated	C	10	M8	25	100	13	38
K0179.2412X65	steel	blue-passivated	C	12	M10	30	65	15	46
K0179.2412X80	steel	blue-passivated	C	12	M10	30	80	15	46
K0179.2412X100	steel	blue-passivated	C	12	M10	30	100	15	46
K0179.2412X125	steel	blue-passivated	C	12	M10	30	125	15	46
K0179.2414X80	steel	blue-passivated	C	14	M12	35	80	16	53
K0179.2414X100	steel	blue-passivated	C	14	M12	35	100	16	53
K0179.2414X125	steel	blue-passivated	C	14	M12	35	125	16	53
K0179.2414X160	steel	blue-passivated	C	14	M12	35	160	16	53
K0179.1408X35	stainless steel	bright	C	8	M6	20	35	9	31
K0179.1408X50	stainless steel	bright	C	8	M6	20	50	9	31
K0179.1408X65	stainless steel	bright	C	8	M6	20	65	9	31
K0179.1410X50	stainless steel	bright	C	10	M8	25	50	13	38
K0179.1410X65	stainless steel	bright	C	10	M8	25	65	13	38
K0179.1410X80	stainless steel	bright	C	10	M8	25	80	13	38

Handles, Form C

Overview of items

Order No.	Main material	Surface finish body	Form	D	D1	D2	L	L1	L2
K0179.1410X100	stainless steel	bright	C	10	M8	25	100	13	38
K0179.1412X65	stainless steel	bright	C	12	M10	30	65	15	46
K0179.1412X80	stainless steel	bright	C	12	M10	30	80	15	46
K0179.1412X100	stainless steel	bright	C	12	M10	30	100	15	46
K0179.1412X125	stainless steel	bright	C	12	M10	30	125	15	46
K0179.1414X80	stainless steel	bright	C	14	M12	35	80	16	53
K0179.1414X100	stainless steel	bright	C	14	M12	35	100	16	53
K0179.1414X125	stainless steel	bright	C	14	M12	35	125	16	53
K0179.1414X160	stainless steel	bright	C	14	M12	35	160	16	53