

Magnets deep pot AlNiCo without fitting tolerance

Item description/product images



Description

Material:

Housing, steel.
Magnetic core AlNiCo.

Version:

Housing, electro zinc-plated.

Note:

Shielded system. Diameter "D" without fitting tolerance. Fastening possibilities are press-in, shrink-fitting or gluing.
Deep pot magnets can be shortened by the dimension "H1" with no loss of magnetic force.


Temperature range:

max. 450°C.

Drawing reference:

1) magnetic face

Drawings

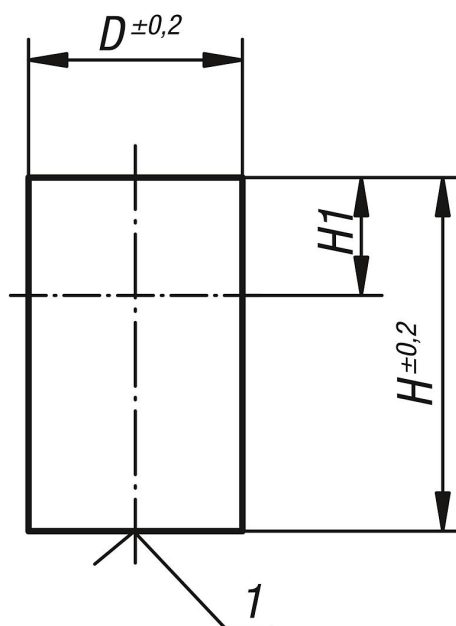

Overview of items

Magnets deep pot AlNiCo without fitting tolerance

Order No.	D	H	H1	Magnetic force N
K0546.01	6	20	12	1,5
K0546.02	8	20	11	3,5
K0546.03	10	20	10	7
K0546.04	13	20	9	10

Magnets deep pot AlNiCo without fitting tolerance

Overview of items

Order No.	D	H	H1	Magnetic force N
K0546.05	16	20	5	18
K0546.06	20	25	6	42
K0546.07	25	35	10	96
K0546.08	32	40	8	180
K0546.09	40	50	10	240