


Subplates

Item description/product images

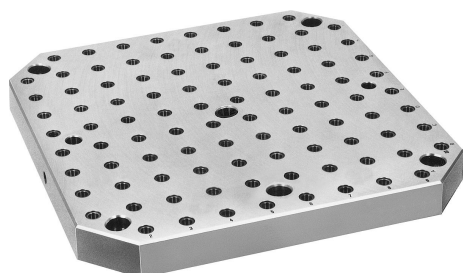

Description

Material:

Grey cast iron GJL 250

Version:

Mounting surfaces ground

Note:

Grid hole pitch 25 ± 0.01 mm or 50 ± 0.01 mm.

Grid hole plugs and ring bolts for lifting are supplied.

These subplates conform to subplates for machine tools according to DIN 55201 and JIS 6337-1980.

The subplates are also available without grid holes. See plates without a value for "A" (xxx/-).

Other dimensions on request.

Overview of items

Subplates

Order No. -	A locating hole	A thread	B	S	No. of grid holes	weight ca. kg
K0806.084040	12F7	M8	55	40	204	36.0000
K0806.124040	12F7/-	M12/-	55	50	59/-	61.0000/117.0000
K0806.004040	12F7/-	M12/-	55	50	59/-	61.0000/117.0000
K0806.125050	12F7	M12	75	50	93	82.0000
K0806.126363	12F7/-	M12/-	100	50	139/-	132.0000/140.0000
K0806.006363	12F7/-	M12/-	100	50	139/-	132.0000/140.0000
K0806.168080	12F7/-	M16/-	135	60	237/-	245.0000/260.0000
K0806.008080	12F7/-	M16/-	135	60	237/-	245.0000/260.0000