

## Telescopic slides, steel for side mounting, full extension, load capacity up to 272 kg

Item description/product images



### Description

#### Material:

Slides steel.  
Ball cages steel.  
Balls, steel.

#### Version:

Slides electro zinc-plated.  
Ball cages, electro zinc-plated.  
Balls hardened.

#### Note for ordering:

Sold individually.

#### Note:

By telescopic slides with full extension, the travel is roughly equal to the installed length, which ensures greater comfort and accessibility. The dynamic load capacity of the telescopic slides indicates the maximum load rating of a vertically mounted slide pair when the entire extension length is used. The load capacities specified refer to the maximum value for 10,000 cycles.

The load capacity is ca. 70% lower by horizontal mounting.

The head height of the fastening screws should not exceed 4,8 mm otherwise there is a risk of collision with other parts of the slide.

These telescopic slides cannot be ordered as a pair.

If single sided latching is desired, a combination with K1719 is possible.

#### Temperature range:

-20 °C - +70 °C.

#### Advantages:

Suitable for flat mounting  
For heavy duty use  
Light running

#### Accessory:

Steel telescopic slides K1719.

#### Note:


The maximum load rating refers to a pair of telescopic slides.

#### Drawing reference:

- 1) Mounting hole by K1720.1524 provided
- 2) Cut-out for carriage bolt

# Telescopic slides, steel for side mounting, full extension, load capacity up to 272 kg

Drawings

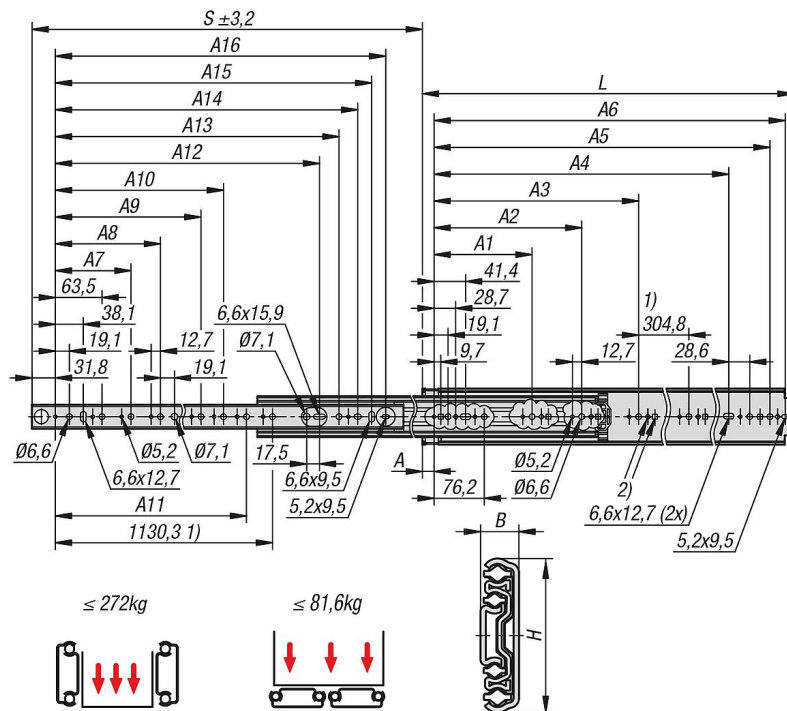

## Overview of items

### Steel telescopic slides for side mounting, full extension, load capacity up to 272 kg

Order No.	Assembly	Product type	Loading per pair kg	Packaging type
K1720.0254	side mounting	standard	272	packaged individually
K1720.0305	side mounting	standard	272	packaged individually
K1720.0356	side mounting	standard	272	packaged individually
K1720.0406	side mounting	standard	272	packaged individually
K1720.0457	side mounting	standard	272	packaged individually
K1720.0508	side mounting	standard	272	packaged individually
K1720.0559	side mounting	standard	272	packaged individually
K1720.0610	side mounting	standard	267	packaged individually
K1720.0660	side mounting	standard	264	packaged individually
K1720.0711	side mounting	standard	261	packaged individually
K1720.0762	side mounting	standard	258	packaged individually
K1720.0813	side mounting	standard	256	packaged individually
K1720.0864	side mounting	standard	253	packaged individually
K1720.0914	side mounting	standard	248	packaged individually
K1720.1016	side mounting	standard	237	packaged individually
K1720.1067	side mounting	standard	228	packaged individually
K1720.1118	side mounting	standard	218	packaged individually
K1720.1220	side mounting	standard	204	packaged individually
K1720.1372	side mounting	standard	196	packaged individually
K1720.1524	side mounting	standard	182	packaged individually

Order No.	A	A1	A2	A3	A4	A5	A6	A7	A8	A9	A10	A11	A12	A13	A14	A15	A16	B	H	Travel S	L
K1720.0254	12,7	-	-	-	152,4	209,6	228,6	-	-	-	-	-	-	103,1	128,5	147,6	166,6	19,1	76,2	254	254
K1720.0305	12,7	-	-	-	203,2	260,4	279,4	-	-	-	-	-	-	153,9	179,3	198,4	217,4	19,1	76,2	304,8	304,8
K1720.0356	12,7	-	-	-	254	311,2	330,2	-	-	-	-	-	-	204,7	230,1	249,2	268,2	19,1	76,2	355,6	355,6
K1720.0406	12,7	-	-	-	304,8	362	381	127	-	-	-	-	-	255,5	280,9	300	319	19,1	76,2	406,4	406,4
K1720.0457	12,7	-	-	-	355,6	412,8	431,8	127	-	-	-	-	246,1	306,3	331,7	350,8	369,8	19,1	76,2	457,2	457,2

## Telescopic slides, steel for side mounting, full extension, load capacity up to 272 kg

### Overview of items

Order No.	A	A1	A2	A3	A4	A5	A6	A7	A8	A9	A10	A11	A12	A13	A14	A15	A16	B	H	Travel S	L
<b>K1720.0508</b>	12,7	-	-	-	406,4	463,6	482,6	127	190,5	-	-	-	296,9	357,1	382,5	401,6	420,6	19,1	76,2	508	508
<b>K1720.0559</b>	12,7	-	-	-	457,2	514,4	533,4	127	190,5	-	-	-	347,7	407,9	433,3	452,4	471,4	19,1	76,2	558,8	558,8
<b>K1720.0610</b>	12,7	-	-	-	508	565,2	584,2	127	190,5	-	-	-	398,5	458,7	484,1	503,2	522,2	19,1	76,2	609,6	609,6
<b>K1720.0660</b>	12,7	-	-	-	558,8	616	635	127	190,5	-	-	-	449,3	509,5	534,9	554	573	19,1	76,2	660,4	660,4
<b>K1720.0711</b>	12,7	-	-	-	609,6	666,8	685,8	127	190,5	-	-	-	500,1	560,3	585,7	604,8	623,8	19,1	76,2	711,2	711,2
<b>K1720.0762</b>	12,7	235	-	501,7	660,4	717,6	736,6	127	190,5	368,3	-	-	550,9	611,1	636,5	655,6	674,6	19,1	76,2	762	762
<b>K1720.0813</b>	12,7	235	393,7	552,5	711,2	768,4	787,4	127	190,5	368,3	-	-	601,7	661,9	687,3	706,4	725,4	19,1	76,2	812,8	812,8
<b>K1720.0864</b>	12,7	235	419,1	603,3	762	819,2	838,2	127	190,5	368,3	469,9	-	652,5	712,7	738,1	757,2	776,2	19,1	76,2	863,6	863,6
<b>K1720.0914</b>	12,7	235	444,5	654,1	812,8	870	889	127	190,5	368,3	520,7	-	703,3	763,5	788,9	808	827	19,1	76,2	914,4	914,4
<b>K1720.1016</b>	12,7	235	546,1	755,7	914,4	971,6	990,6	127	190,5	368,3	520,7	-	804,9	865,1	890,5	909,6	928,6	19,1	76,2	1016	1016
<b>K1720.1067</b>	12,7	235	546,1	806,5	965,2	1022,4	1041,4	127	190,5	368,3	520,7	-	855,7	915,9	941,3	960,4	979,4	19,1	76,2	1066,8	1066,8
<b>K1720.1118</b>	12,7	235	546,1	857,3	1016	1073,2	1092,2	127	190,5	368,3	520,7	-	906,5	966,7	992,1	1011,2	1030,2	19,1	76,2	1117,6	1117,6
<b>K1720.1220</b>	12,7	235	596,9	958,9	1117,6	1174,8	1193,8	127	190,5	368,3	520,7	825,5	1008,1	1068,3	1093,7	1112,8	1131,8	19,1	76,2	1219,2	1219,2
<b>K1720.1372</b>	12,7	235	596,9	958,9	1270	1327,2	1346,2	127	190,5	368,3	520,7	825,5	1160,5	1220,8	1246,2	1265,2	1284,2	19,1	76,2	1371,6	1371,6
<b>K1720.1524</b>	12,7	235	596,9	958,9	1422,4	1479,6	1498,6	127	190,5	368,3	520,7	825,5	1312,9	1373,1	1398,5	1417,6	1436,6	19,1	76,2	1524	1524